

1064nm, 45° AOI, Polarization Phase Maintining Mirrors


Coating Specification:

R avg S & P \geq 99.90% @ 1064nm @ 45° AOI

R avg \geq 99 % @ 1000 – 1100nm @ 45° AOI

R avg \geq 80% @ 650nm @ 45° AOI

Theoretical Phase Curve

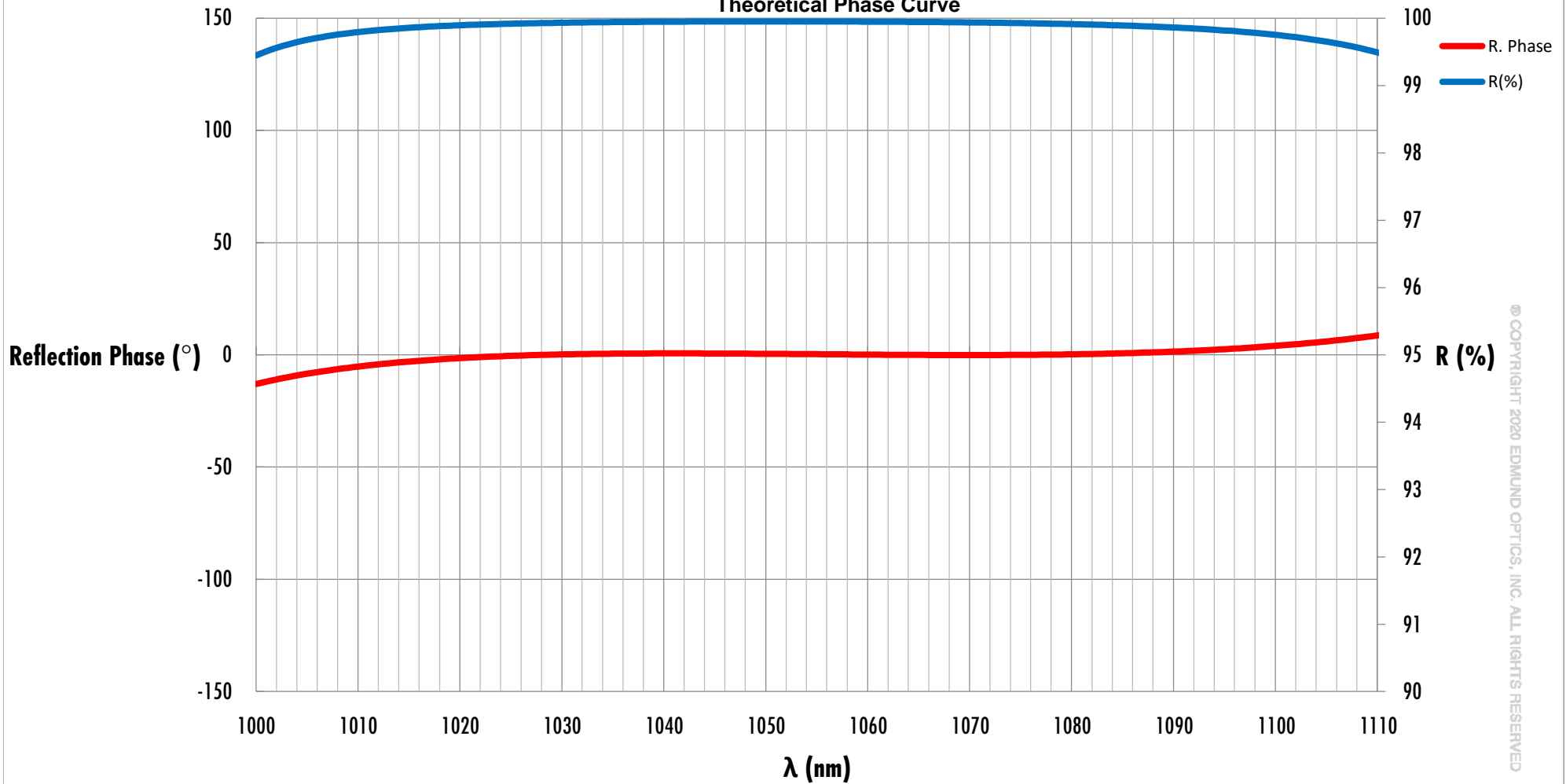

© COPYRIGHT 2020 EDMUND OPTICS, INC. ALL RIGHTS RESERVED