

[All Products](#) / [Optics](#) / [Optical Lenses](#) / [Double-Convex \(DCX\) Lenses](#)

TECHSPEC® UV Fused Silica Double-Convex (DCX) Lenses



- Ideal for Imaging Applications
- Minimize Aberrations Including Spherical and Coma
- Precision Fused Silica Substrate

Common Specifications

Physical & Mechanical Properties


Bevel: Protective as needed

Optical Properties


Substrate: [Fused Silica](#) (Corning 7980)

Surface Quality:	40-20	Power (P-V) @ 632.8nm:	1.5λ
Irregularity (P-V) @ 632.8nm:	λ/4	Focal Length Specification Wavelength (nm):	587.6
Focal Length Tolerance (%):	±1		


Technical Information

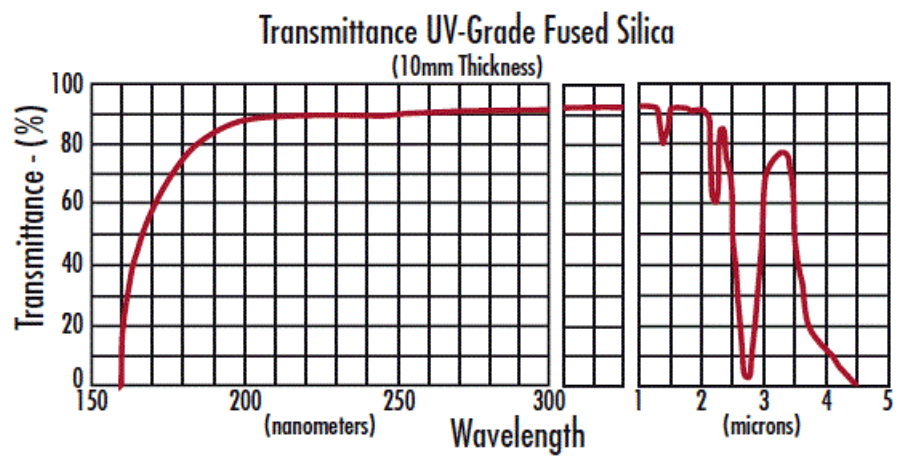


UV FS Transmission Curve

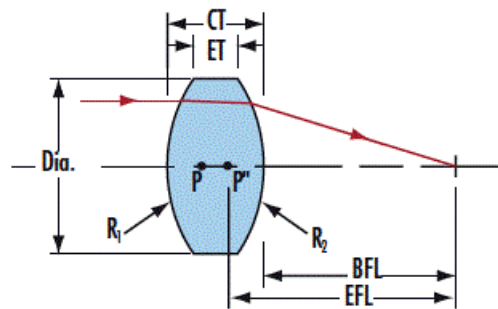

Standard Visible Anti-Reflection Coatings

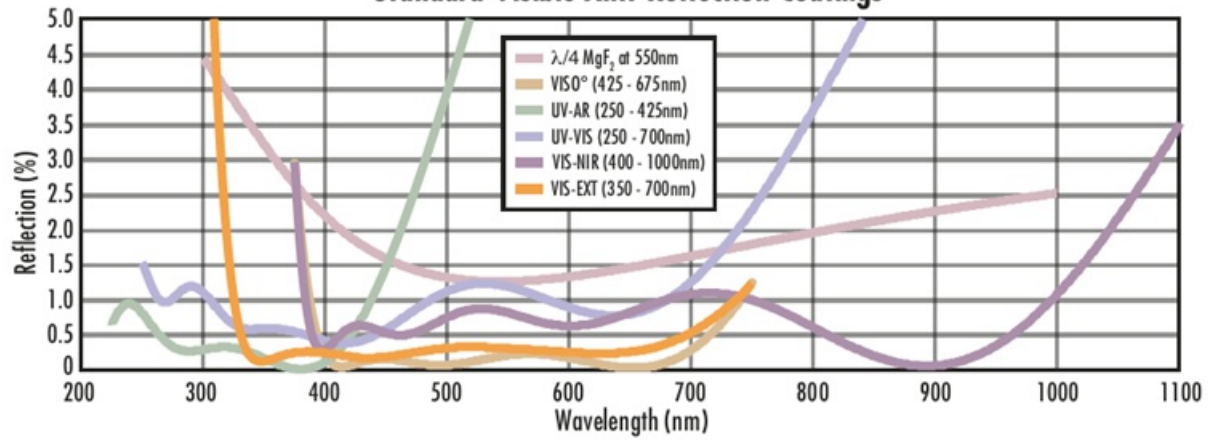

Standard Near Infrared Anti-Reflection Coatings

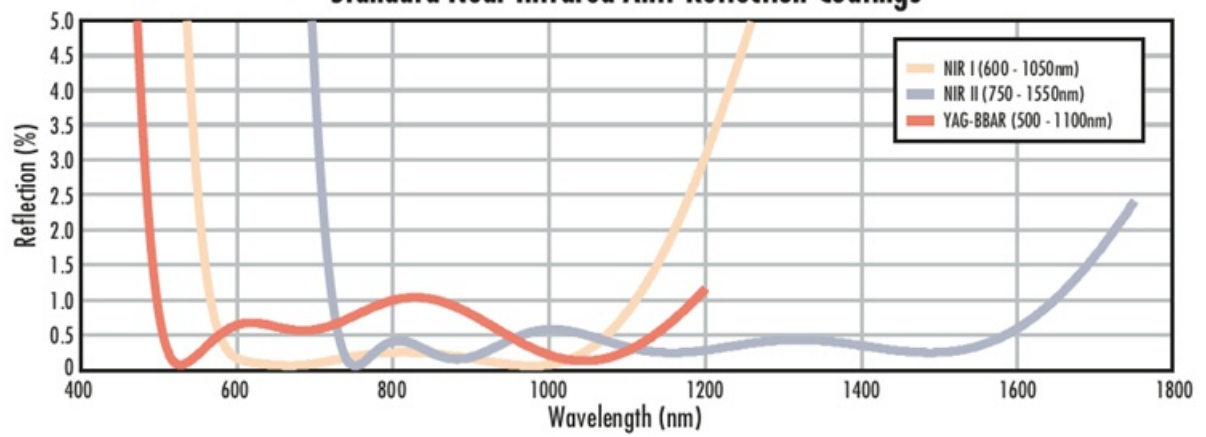

Products

Dia. (mm)	BFL (mm)	EFL (mm)	Coating	Substrate	Stock Number	Price	Buy
6.00	4.38	6.00	Uncoated	Fused Silica	#49-238	€120,51 Volume Pricing	20+ In Stock
6.00	4.38	6.00	UV-AR (250-425nm)	Fused Silica	#49-246	€142,14 Volume Pricing	20+ In Stock
6.00	4.38	6.00	UV-VIS (250-700nm)	Fused Silica	#49-254	€142,14 Volume Pricing	16 In Stock
6.00	4.38	6.00	VIS-EXT (350-700nm)	Fused Silica	#22-196	€142,14 Volume Pricing	8 In Stock
6.00	4.38	6.00	VIS 0° (425-675nm)	Fused Silica	#49-262	€140,08 Volume Pricing	Contact Us
6.00	4.38	6.00	VIS-NIR (400-1000nm)	Fused Silica	#63-817	€142,14 Volume Pricing	13 In Stock
6.00	4.38	6.00	NIR I (600-1050nm)	Fused Silica	#22-156	€140,08 Volume Pricing	7 In Stock
6.00	4.38	6.00	NIR II (750-1550nm)	Fused Silica	#22-176	€140,08 Volume Pricing	2 In Stock
6.00	8.02	9.00	Uncoated	Fused Silica	#49-239	€120,51 Volume Pricing	6 In Stock
6.00	8.02	9.00	UV-AR (250-425nm)	Fused Silica	#49-247	€142,14 Volume Pricing	7 In Stock
6.00	8.02	9.00	UV-VIS (250-700nm)	Fused Silica	#49-255	€142,14 Volume Pricing	20+ In Stock
6.00	8.02	9.00	VIS 0° (425-675nm)	Fused Silica	#49-263	€140,08 Volume Pricing	20+ In Stock
6.00	8.02	9.00	VIS-NIR (400-1000nm)	Fused Silica	#63-818	€142,14 Volume Pricing	12 In Stock
6.00	11.23	12.00	Uncoated	Fused Silica	#49-240	€120,51 Volume Pricing	20+ In Stock

6.00	11.23	12.00	UV-AR (250-425nm)	Fused Silica	#49-248	€142,14 Volume Pricing	1 In Stock
6.00	11.23	12.00	UV-VIS (250-700nm)	Fused Silica	#49-256	€142,14 Volume Pricing	5 In Stock
6.00	11.23	12.00	VIS-EXT (350-700nm)	Fused Silica	#22-195	€142,14 Volume Pricing	3 In Stock
6.00	11.23	12.00	VIS 0° (425-675nm)	Fused Silica	#49-264	€140,08 Volume Pricing	12 In Stock
6.00	11.23	12.00	VIS-NIR (400-1000nm)	Fused Silica	#63-819	€142,14 Volume Pricing	20+ In Stock
6.00	11.23	12.00	NIR I (600-1050nm)	Fused Silica	#22-155	€140,08 Volume Pricing	5 In Stock
6.00	11.23	12.00	NIR II (750-1550nm)	Fused Silica	#22-175	€140,08 Volume Pricing	2 In Stock
6.00	17.30	18.00	Uncoated	Fused Silica	#49-983	€115,36 Volume Pricing	20+ In Stock
6.00	17.30	18.00	UV-AR (250-425nm)	Fused Silica	#49-987	€136,99 Volume Pricing	5 In Stock
6.00	17.30	18.00	UV-VIS (250-700nm)	Fused Silica	#49-991	€136,99 Volume Pricing	8 In Stock
6.00	17.30	18.00	VIS 0° (425-675nm)	Fused Silica	#49-995	€134,93 Volume Pricing	5 In Stock
6.00	17.30	18.00	VIS-NIR (400-1000nm)	Fused Silica	#63-820	€136,99 Volume Pricing	16 In Stock
6.00	23.31	24.00	Uncoated	Fused Silica	#49-984	€115,36 Volume Pricing	20+ In Stock
6.00	23.31	24.00	UV-AR (250-425nm)	Fused Silica	#49-988	€136,99 Volume Pricing	5 In Stock
6.00	23.31	24.00	UV-VIS (250-700nm)	Fused Silica	#49-992	€136,99 Volume Pricing	Contact Us
6.00	23.31	24.00	VIS 0° (425-675nm)	Fused Silica	#49-996	€134,93 Volume Pricing	13 In Stock

6.00	23.31	24.00	VIS-NIR (400-1000nm)	Fused Silica	#63-821	€136,99 Volume Pricing	20+ In Stock
9.00	7.12	9.00	Uncoated	Fused Silica	#49-241	€123,60 Volume Pricing	20+ In Stock
9.00	7.12	9.00	UV-AR (250-425nm)	Fused Silica	#49-249	€145,23 Volume Pricing	20+ In Stock
9.00	7.12	9.00	UV-VIS (250-700nm)	Fused Silica	#49-257	€145,23 Volume Pricing	13 In Stock
9.00	7.12	9.00	VIS-EXT (350-700nm)	Fused Silica	#22-200	€145,23 Volume Pricing	4 In Stock
9.00	7.12	9.00	VIS 0° (425-675nm)	Fused Silica	#49-265	€143,17 Volume Pricing	5 In Stock
9.00	7.12	9.00	VIS-NIR (400-1000nm)	Fused Silica	#63-822	€145,23 Volume Pricing	7 In Stock
9.00	7.12	9.00	NIR I (600-1050nm)	Fused Silica	#22-160	€143,17 Volume Pricing	2 In Stock
9.00	7.12	9.00	NIR II (750-1550nm)	Fused Silica	#22-180	€143,17 Volume Pricing	4 In Stock
9.00	12.32	13.50	Uncoated	Fused Silica	#49-242	€123,60 Volume Pricing	20+ In Stock
9.00	12.32	13.50	UV-AR (250-425nm)	Fused Silica	#49-250	€145,23 Volume Pricing	4 In Stock
9.00	12.32	13.50	UV-VIS (250-700nm)	Fused Silica	#49-258	€145,23 Volume Pricing	1 In Stock
9.00	12.32	13.50	VIS-EXT (350-700nm)	Fused Silica	#22-197	€145,23 Volume Pricing	1 In Stock
9.00	12.32	13.50	VIS 0° (425-675nm)	Fused Silica	#49-266	€143,17 Volume Pricing	5 In Stock
9.00	12.32	13.50	VIS-NIR (400-1000nm)	Fused Silica	#63-823	€145,23 Volume Pricing	20+ In Stock
9.00	12.32	13.50	NIR I (600-1050nm)	Fused Silica	#22-157	€143,17 Volume Pricing	4 In Stock

9.00	12.32	13.50	NIR II (750-1550nm)	Fused Silica	#22-177	€143,17 Volume Pricing	5 In Stock
9.00	17.09	18.00	Uncoated	Fused Silica	#49-243	€123,60 Volume Pricing	20+ In Stock
9.00	17.09	18.00	UV-AR (250-425nm)	Fused Silica	#49-251	€145,23 Volume Pricing	20+ In Stock
9.00	17.09	18.00	UV-VIS (250-700nm)	Fused Silica	#49-259	€145,23 Volume Pricing	Contact Us
9.00	17.09	18.00	VIS-EXT (350-700nm)	Fused Silica	#22-198	€145,23 Volume Pricing	4 In Stock
9.00	17.09	18.00	VIS 0° (425-675nm)	Fused Silica	#49-267	€143,17 Volume Pricing	Contact Us
9.00	17.09	18.00	VIS-NIR (400-1000nm)	Fused Silica	#63-824	€145,23 Volume Pricing	14 In Stock
9.00	17.09	18.00	NIR I (600-1050nm)	Fused Silica	#22-158	€143,17 Volume Pricing	5 In Stock
9.00	17.09	18.00	NIR II (750-1550nm)	Fused Silica	#22-178	€143,17 Volume Pricing	4 In Stock
9.00	26.13	27.00	Uncoated	Fused Silica	#49-985	€118,45 Volume Pricing	20+ In Stock
9.00	26.13	27.00	UV-AR (250-425nm)	Fused Silica	#49-989	€140,08 Volume Pricing	3 In Stock
9.00	26.13	27.00	UV-VIS (250-700nm)	Fused Silica	#49-993	€140,08 Volume Pricing	14 In Stock
9.00	26.13	27.00	VIS-EXT (350-700nm)	Fused Silica	#22-199	€140,08 Volume Pricing	5 In Stock
9.00	26.13	27.00	VIS 0° (425-675nm)	Fused Silica	#49-997	€136,99 Volume Pricing	8 In Stock
9.00	26.13	27.00	VIS-NIR (400-1000nm)	Fused Silica	#63-825	€140,08 Volume Pricing	20+ In Stock
9.00	26.13	27.00	NIR I (600-1050nm)	Fused Silica	#22-159	€136,99 Volume Pricing	5 In Stock

9.00	26.13	27.00	NIR II (750-1550nm)	Fused Silica	#22-179	€136,99 Volume Pricing	5 In Stock
9.00	35.31	36.00	Uncoated	Fused Silica	#49-986	€118,45 Volume Pricing	20+ In Stock
9.00	35.31	36.00	UV-AR (250-425nm)	Fused Silica	#49-990	€140,08 Volume Pricing	1 In Stock
9.00	35.31	36.00	UV-VIS (250-700nm)	Fused Silica	#49-994	€140,08 Volume Pricing	20+ In Stock
9.00	35.31	36.00	VIS 0° (425-675nm)	Fused Silica	#49-998	€136,99 Volume Pricing	8 In Stock
9.00	35.31	36.00	VIS-NIR (400-1000nm)	Fused Silica	#63-826	€140,08 Volume Pricing	20+ In Stock
12.00	9.25	12.00	Uncoated	Fused Silica	#48-034	€123,60 Volume Pricing	20+ In Stock
12.00	9.25	12.00	UV-AR (250-425nm)	Fused Silica	#48-040	€148,32 Volume Pricing	14 In Stock
12.00	9.25	12.00	UV-VIS (250-700nm)	Fused Silica	#48-834	€148,32 Volume Pricing	7 In Stock
12.00	9.25	12.00	VIS-EXT (350-700nm)	Fused Silica	#22-203	€148,32 Volume Pricing	2 In Stock
12.00	9.25	12.00	VIS 0° (425-675nm)	Fused Silica	#48-974	€145,23 Volume Pricing	9 In Stock
12.00	9.25	12.00	VIS-NIR (400-1000nm)	Fused Silica	#63-827	€148,32 Volume Pricing	20+ In Stock
12.00	9.25	12.00	NIR I (600-1050nm)	Fused Silica	#22-163	€145,23 Volume Pricing	3 In Stock
12.00	9.25	12.00	NIR II (750-1550nm)	Fused Silica	#22-183	€145,23 Volume Pricing	7 In Stock
12.00	13.37	15.00	Uncoated	Fused Silica	#49-244	€123,60 Volume Pricing	20+ In Stock
12.00	13.37	15.00	UV-AR (250-425nm)	Fused Silica	#49-252	€148,32 Volume Pricing	5 In Stock

12.00	13.37	15.00	UV-VIS (250-700nm)	Fused Silica	#49-260	€148,32 Volume Pricing	13 In Stock
12.00	13.37	15.00	VIS-EXT (350-700nm)	Fused Silica	#22-204	€148,32 Volume Pricing	14 In Stock
12.00	13.37	15.00	VIS 0° (425-675nm)	Fused Silica	#49-268	€145,23 Volume Pricing	2 In Stock
12.00	13.37	15.00	VIS-NIR (400-1000nm)	Fused Silica	#63-828	€148,32 Volume Pricing	20+ In Stock
12.00	13.37	15.00	NIR I (600-1050nm)	Fused Silica	#22-164	€145,23 Volume Pricing	3 In Stock
12.00	13.37	15.00	NIR II (750-1550nm)	Fused Silica	#22-184	€145,23 Volume Pricing	3 In Stock
12.00	18.44	20.00	Uncoated	Fused Silica	#48-035	€123,60 Volume Pricing	13 In Stock
12.00	18.44	20.00	UV-AR (250-425nm)	Fused Silica	#48-041	€148,32 Volume Pricing	Contact Us
12.00	18.44	20.00	UV-VIS (250-700nm)	Fused Silica	#48-835	€148,32 Volume Pricing	Contact Us
12.00	18.44	20.00	VIS-EXT (350-700nm)	Fused Silica	#22-205	€148,32 Volume Pricing	5 In Stock
12.00	18.44	20.00	VIS 0° (425-675nm)	Fused Silica	#48-975	€145,23 Volume Pricing	15 In Stock
12.00	18.44	20.00	VIS-NIR (400-1000nm)	Fused Silica	#63-829	€148,32 Volume Pricing	20+ In Stock
12.00	18.44	20.00	NIR I (600-1050nm)	Fused Silica	#22-165	€145,23 Volume Pricing	5 In Stock
12.00	18.44	20.00	NIR II (750-1550nm)	Fused Silica	#22-185	€145,23 Volume Pricing	5 In Stock
12.00	22.92	24.00	Uncoated	Fused Silica	#49-245	€123,60 Volume Pricing	20+ In Stock
12.00	22.92	24.00	UV-AR (250-425nm)	Fused Silica	#49-253	€148,32 Volume Pricing	2 In Stock

12.00	22.92	24.00	UV-VIS (250-700nm)	Fused Silica	#49-261	€148,32 Volume Pricing	Contact Us
12.00	22.92	24.00	VIS-EXT (350-700nm)	Fused Silica	#22-206	€148,32 Volume Pricing	5 In Stock
12.00	22.92	24.00	VIS 0° (425-675nm)	Fused Silica	#49-269	€145,23 Volume Pricing	5 In Stock
12.00	22.92	24.00	VIS-NIR (400-1000nm)	Fused Silica	#63-830	€148,32 Volume Pricing	20+ In Stock
12.00	22.92	24.00	NIR I (600-1050nm)	Fused Silica	#22-166	€145,23 Volume Pricing	4 In Stock
12.00	22.92	24.00	NIR II (750-1550nm)	Fused Silica	#22-186	€145,23 Volume Pricing	5 In Stock
12.00	28.77	30.00	Uncoated	Fused Silica	#48-036	€117,42 Volume Pricing	20+ In Stock
12.00	28.77	30.00	UV-AR (250-425nm)	Fused Silica	#48-042	€142,14 Volume Pricing	4 In Stock
12.00	28.77	30.00	UV-VIS (250-700nm)	Fused Silica	#48-836	€142,14 Volume Pricing	6 In Stock
12.00	28.77	30.00	VIS-EXT (350-700nm)	Fused Silica	#22-201	€142,14 Volume Pricing	4 In Stock
12.00	28.77	30.00	VIS 0° (425-675nm)	Fused Silica	#48-976	€139,05 Volume Pricing	8 In Stock
12.00	28.77	30.00	VIS-NIR (400-1000nm)	Fused Silica	#63-831	€142,14 Volume Pricing	12 In Stock
12.00	28.77	30.00	NIR I (600-1050nm)	Fused Silica	#22-161	€139,05 Volume Pricing	4 In Stock
12.00	28.77	30.00	NIR II (750-1550nm)	Fused Silica	#22-181	€139,05 Volume Pricing	5 In Stock
12.00	33.85	35.00	Uncoated	Fused Silica	#48-037	€117,42 Volume Pricing	20+ In Stock
12.00	33.85	35.00	UV-AR (250-425nm)	Fused Silica	#48-043	€142,14 Volume Pricing	Contact Us

12.00	33.85	35.00	UV-VIS (250-700nm)	Fused Silica	#48-837	€142,14 Volume Pricing	Contact Us
12.00	33.85	35.00	VIS-EXT (350-700nm)	Fused Silica	#22-202	€142,14 Volume Pricing	1 In Stock
12.00	33.85	35.00	VIS 0° (425-675nm)	Fused Silica	#48-977	€139,05 Volume Pricing	9 In Stock
12.00	33.85	35.00	VIS-NIR (400-1000nm)	Fused Silica	#63-832	€142,14 Volume Pricing	14 In Stock
12.00	33.85	35.00	NIR I (600-1050nm)	Fused Silica	#22-162	€139,05 Volume Pricing	3 In Stock
12.00	33.85	35.00	NIR II (750-1550nm)	Fused Silica	#22-182	€139,05 Volume Pricing	4 In Stock
12.00	43.96	45.00	Uncoated	Fused Silica	#48-038	€117,42 Volume Pricing	20+ In Stock
12.00	43.96	45.00	UV-AR (250-425nm)	Fused Silica	#48-044	€142,14 Volume Pricing	1 In Stock
12.00	43.96	45.00	UV-VIS (250-700nm)	Fused Silica	#48-838	€142,14 Volume Pricing	Contact Us
12.00	43.96	45.00	VIS 0° (425-675nm)	Fused Silica	#48-978	€139,05 Volume Pricing	1 In Stock
12.00	43.96	45.00	VIS-NIR (400-1000nm)	Fused Silica	#63-833	€142,14 Volume Pricing	20+ In Stock
12.00	74.11	75.00	Uncoated	Fused Silica	#48-039	€117,42 Volume Pricing	7 In Stock
12.00	74.11	75.00	UV-VIS (250-700nm)	Fused Silica	#48-839	€142,14 Volume Pricing	12 In Stock
12.00	74.11	75.00	UV-AR (250-425nm)	Fused Silica	#48-045	€142,14 Volume Pricing	4 In Stock
12.00	74.11	75.00	VIS-EXT (350-700nm)	Fused Silica	#22-207	€142,14 Volume Pricing	2 In Stock
12.00	74.11	75.00	VIS 0° (425-675nm)	Fused Silica	#48-979	€139,05 Volume Pricing	15 In Stock

12.00	74.11	75.00	VIS-NIR (400-1000nm)	Fused Silica	#63-834	€142,14 Volume Pricing	16 In Stock
12.00	74.11	75.00	NIR I (600-1050nm)	Fused Silica	#22-167	€139,05 Volume Pricing	5 In Stock
12.00	74.11	75.00	NIR II (750-1550nm)	Fused Silica	#22-187	€139,05 Volume Pricing	4 In Stock
18.00	17.18	20.00	Uncoated	Fused Silica	#08-083	€131,84 Volume Pricing	Contact Us
18.00	17.18	20.00	UV-AR (250-425nm)	Fused Silica	#46-290	€155,53 Volume Pricing	20+ In Stock
18.00	17.18	20.00	UV-VIS (250-700nm)	Fused Silica	#48-840	€155,53 Volume Pricing	1 In Stock
18.00	17.18	20.00	VIS-EXT (350-700nm)	Fused Silica	#22-208	€155,53 Volume Pricing	4 In Stock
18.00	17.18	20.00	VIS 0° (425-675nm)	Fused Silica	#48-980	€153,47 Volume Pricing	14 In Stock
18.00	17.18	20.00	VIS-NIR (400-1000nm)	Fused Silica	#63-835	€155,53 Volume Pricing	7 In Stock
18.00	17.18	20.00	NIR I (600-1050nm)	Fused Silica	#22-168	€153,47 Volume Pricing	3 In Stock
18.00	17.18	20.00	NIR II (750-1550nm)	Fused Silica	#22-188	€153,47 Volume Pricing	5 In Stock
18.00	38.50	40.00	Uncoated	Fused Silica	#08-084	€131,84 Volume Pricing	11 In Stock
18.00	38.50	40.00	UV-AR (250-425nm)	Fused Silica	#46-291	€155,53 Volume Pricing	3 In Stock
18.00	38.50	40.00	UV-VIS (250-700nm)	Fused Silica	#48-841	€155,53 Volume Pricing	Contact Us
18.00	38.50	40.00	VIS-EXT (350-700nm)	Fused Silica	#22-209	€155,53 Volume Pricing	5 In Stock
18.00	38.50	40.00	VIS 0° (425-675nm)	Fused Silica	#48-981	€153,47 Volume Pricing	8 In Stock

18.00	38.50	40.00	VIS-NIR (400-1000nm)	Fused Silica	#63-836	€155,53 Volume Pricing	1 In Stock
18.00	38.50	40.00	NIR I (600-1050nm)	Fused Silica	#22-169	€153,47 Volume Pricing	5 In Stock
18.00	38.50	40.00	NIR II (750-1550nm)	Fused Silica	#22-189	€153,47 Volume Pricing	5 In Stock
25.00	20.93	25.00	Uncoated	Fused Silica	#48-293	€139,05 Volume Pricing	20+ In Stock
25.00	20.93	25.00	UV-AR (250-425nm)	Fused Silica	#48-304	€162,74 Volume Pricing	20+ In Stock
25.00	20.93	25.00	UV-VIS (250-700nm)	Fused Silica	#48-842	€162,74 Volume Pricing	20+ In Stock
25.00	20.93	25.00	VIS-EXT (350-700nm)	Fused Silica	#22-212	€162,74 Volume Pricing	3 In Stock
25.00	20.93	25.00	VIS 0° (425-675nm)	Fused Silica	#48-982	€160,68 Volume Pricing	14 In Stock
25.00	20.93	25.00	VIS-NIR (400-1000nm)	Fused Silica	#63-837	€162,74 Volume Pricing	8 In Stock
25.00	20.93	25.00	NIR I (600-1050nm)	Fused Silica	#22-172	€160,68 Volume Pricing	9 In Stock
25.00	20.93	25.00	NIR II (750-1550nm)	Fused Silica	#22-192	€160,68 Volume Pricing	14 In Stock
25.00	48.02	50.00	Uncoated	Fused Silica	#48-294	€139,05 Volume Pricing	20+ In Stock
25.00	48.02	50.00	UV-AR (250-425nm)	Fused Silica	#48-305	€162,74 Volume Pricing	20+ In Stock
25.00	48.02	50.00	UV-VIS (250-700nm)	Fused Silica	#48-843	€162,74 Volume Pricing	8 In Stock
25.00	48.02	50.00	VIS-EXT (350-700nm)	Fused Silica	#22-213	€162,74 Volume Pricing	5 In Stock
25.00	48.02	50.00	VIS 0° (425-675nm)	Fused Silica	#48-983	€160,68 Volume Pricing	16 In Stock

25.00	48.02	50.00	VIS-NIR (400-1000nm)	Fused Silica	#63-838	€162,74 Volume Pricing	7 In Stock
25.00	48.02	50.00	NIR I (600-1050nm)	Fused Silica	#22-173	€160,68 Volume Pricing	5 In Stock
25.00	48.02	50.00	NIR II (750-1550nm)	Fused Silica	#22-193	€160,68 Volume Pricing	Contact Us
25.00	58.08	60.00	Uncoated	Fused Silica	#48-295	€133,90 Volume Pricing	13 In Stock
25.00	58.08	60.00	UV-AR (250-425nm)	Fused Silica	#48-306	€157,59 Volume Pricing	14 In Stock
25.00	58.08	60.00	UV-VIS (250-700nm)	Fused Silica	#48-844	€157,59 Volume Pricing	4 In Stock
25.00	58.08	60.00	VIS-EXT (350-700nm)	Fused Silica	#22-214	€157,59 Volume Pricing	4 In Stock
25.00	58.08	60.00	VIS 0° (425-675nm)	Fused Silica	#48-984	€155,53 Volume Pricing	4 In Stock
25.00	58.08	60.00	VIS-NIR (400-1000nm)	Fused Silica	#63-839	€157,59 Volume Pricing	12 In Stock
25.00	58.08	60.00	NIR I (600-1050nm)	Fused Silica	#22-174	€155,53 Volume Pricing	4 In Stock
25.00	58.08	60.00	NIR II (750-1550nm)	Fused Silica	#22-194	€155,53 Volume Pricing	4 In Stock
25.00	73.91	75.60	Uncoated	Fused Silica	#48-296	€133,90 Volume Pricing	11 In Stock
25.00	73.91	75.60	UV-AR (250-425nm)	Fused Silica	#48-307	€157,59 Volume Pricing	Contact Us
25.00	73.91	75.60	UV-VIS (250-700nm)	Fused Silica	#48-845	€157,59 Volume Pricing	3 In Stock
25.00	73.91	75.60	VIS-EXT (350-700nm)	Fused Silica	#22-210	€157,59 Volume Pricing	3 In Stock
25.00	73.91	75.60	VIS 0° (425-675nm)	Fused Silica	#48-985	€155,53 Volume Pricing	11 In Stock

25.00	73.91	75.60	VIS-NIR (400-1000nm)	Fused Silica	#63-840	€157,59 Volume Pricing	8 In Stock
25.00	73.91	75.60	NIR I (600-1050nm)	Fused Silica	#22-170	€155,53 Volume Pricing	5 In Stock
25.00	73.91	75.60	NIR II (750-1550nm)	Fused Silica	#22-190	€155,53 Volume Pricing	1 In Stock
25.00	98.70	100.00	Uncoated	Fused Silica	#48-297	€133,90 Volume Pricing	15 In Stock
25.00	98.70	100.00	UV-AR (250-425nm)	Fused Silica	#48-308	€157,59 Volume Pricing	13 In Stock
25.00	98.70	100.00	UV-VIS (250-700nm)	Fused Silica	#48-846	€157,59 Volume Pricing	11 In Stock
25.00	98.70	100.00	VIS-EXT (350-700nm)	Fused Silica	#22-211	€157,59 Volume Pricing	8 In Stock
25.00	98.70	100.00	VIS 0° (425-675nm)	Fused Silica	#48-986	€155,53 Volume Pricing	7 In Stock
25.00	98.70	100.00	VIS-NIR (400-1000nm)	Fused Silica	#63-841	€157,59 Volume Pricing	2 In Stock
25.00	98.70	100.00	NIR I (600-1050nm)	Fused Silica	#22-171	€155,53 Volume Pricing	4 In Stock
25.00	98.70	100.00	NIR II (750-1550nm)	Fused Silica	#22-191	€155,53 Volume Pricing	3 In Stock
25.00	123.82	125.00	Uncoated	Fused Silica	#48-298	€127,72 Volume Pricing	20+ In Stock
25.00	123.82	125.00	UV-AR (250-425nm)	Fused Silica	#48-309	€152,44 Volume Pricing	4 In Stock
25.00	123.82	125.00	UV-VIS (250-700nm)	Fused Silica	#48-847	€152,44 Volume Pricing	10 In Stock
25.00	123.82	125.00	VIS 0° (425-675nm)	Fused Silica	#48-987	€149,35 Volume Pricing	14 In Stock
25.00	123.82	125.00	VIS-NIR (400-1000nm)	Fused Silica	#63-842	€152,44 Volume Pricing	5 In Stock

25.00	148.37	150.00	Uncoated	Fused Silica	#48-299	€127,72 Volume Pricing	20+ In Stock
25.00	148.37	150.00	UV-AR (250-425nm)	Fused Silica	#48-310	€152,44 Volume Pricing	16 In Stock
25.00	148.37	150.00	UV-VIS (250-700nm)	Fused Silica	#48-848	€152,44 Volume Pricing	2 In Stock
25.00	148.37	150.00	VIS 0° (425-675nm)	Fused Silica	#48-988	€149,35 Volume Pricing	7 In Stock
25.00	148.37	150.00	VIS-NIR (400-1000nm)	Fused Silica	#63-843	€152,44 Volume Pricing	4 In Stock
25.00	198.84	200.00	Uncoated	Fused Silica	#48-300	€127,72 Volume Pricing	5 In Stock
25.00	198.84	200.00	UV-AR (250-425nm)	Fused Silica	#48-311	€152,44 Volume Pricing	20+ In Stock
25.00	198.84	200.00	UV-VIS (250-700nm)	Fused Silica	#48-849	€152,44 Volume Pricing	Contact Us
25.00	198.84	200.00	VIS 0° (425-675nm)	Fused Silica	#48-989	€149,35 Volume Pricing	20+ In Stock
25.00	198.84	200.00	VIS-NIR (400-1000nm)	Fused Silica	#63-844	€152,44 Volume Pricing	1 In Stock
25.00	248.90	250.00	Uncoated	Fused Silica	#48-301	€127,72 Volume Pricing	20+ In Stock
25.00	248.90	250.00	UV-AR (250-425nm)	Fused Silica	#48-312	€152,44 Volume Pricing	6 In Stock
25.00	248.90	250.00	UV-VIS (250-700nm)	Fused Silica	#48-850	€152,44 Volume Pricing	Contact Us
25.00	248.90	250.00	VIS 0° (425-675nm)	Fused Silica	#48-990	€149,35 Volume Pricing	5 In Stock
25.00	248.90	250.00	VIS-NIR (400-1000nm)	Fused Silica	#63-845	€152,44 Volume Pricing	5 In Stock
25.00	298.94	300.00	Uncoated	Fused Silica	#48-302	€127,72 Volume Pricing	20+ In Stock

25.00	298.94	300.00	UV-AR (250-425nm)	Fused Silica	#48-313	€152,44 Volume Pricing	14 In Stock
25.00	298.94	300.00	UV-VIS (250-700nm)	Fused Silica	#48-851	€152,44 Volume Pricing	6 In Stock
25.00	298.94	300.00	VIS 0° (425-675nm)	Fused Silica	#48-991	€149,35 Volume Pricing	20+ In Stock
25.00	298.94	300.00	VIS-NIR (400-1000nm)	Fused Silica	#63-846	€152,44 Volume Pricing	4 In Stock
25.00	498.85	500.00	Uncoated	Fused Silica	#48-303	€127,72 Volume Pricing	12 In Stock
25.00	498.85	500.00	UV-AR (250-425nm)	Fused Silica	#48-314	€152,44 Volume Pricing	20+ In Stock
25.00	498.85	500.00	UV-VIS (250-700nm)	Fused Silica	#48-852	€152,44 Volume Pricing	7 In Stock
25.00	498.85	500.00	VIS 0° (425-675nm)	Fused Silica	#48-992	€149,35 Volume Pricing	6 In Stock
25.00	498.85	500.00	VIS-NIR (400-1000nm)	Fused Silica	#63-847	€152,44 Volume Pricing	3 In Stock
30.00	25.12	30.00	Uncoated	Fused Silica	#22-413	€159,65 Volume Pricing	5 In Stock
30.00	25.12	30.00	UV-AR (250-425nm)	Fused Silica	#26-600	€190,55 Volume Pricing	4 In Stock
30.00	25.12	30.00	UV-VIS (250-700nm)	Fused Silica	#26-606	€185,40 Volume Pricing	1 In Stock
30.00	25.12	30.00	VIS 0° (425-675nm)	Fused Silica	#26-612	€190,55 Volume Pricing	2 In Stock
30.00	25.12	30.00	VIS-NIR (400-1000nm)	Fused Silica	#26-618	€190,55 Volume Pricing	1 In Stock
40.00	33.49	40.00	Uncoated	Fused Silica	#22-420	€178,19 Volume Pricing	Contact Us

40.00	33.49	40.00	UV-AR (250-425nm)	Fused Silica	#26-601	€212,18 Volume Pricing	1 In Stock
40.00	33.49	40.00	UV-VIS (250-700nm)	Fused Silica	#26-607	€207,03 Volume Pricing	2 In Stock
40.00	33.49	40.00	VIS 0° (425-675nm)	Fused Silica	#26-613	€212,18 Volume Pricing	5 In Stock
40.00	33.49	40.00	VIS-NIR (400-1000nm)	Fused Silica	#26-619	€212,18 Volume Pricing	4 In Stock
50.00	41.87	50.00	Uncoated	Fused Silica	#22-426	€299,73 Volume Pricing	20+ In Stock
50.00	41.87	50.00	UV-AR (250-425nm)	Fused Silica	#26-602	€330,63 Volume Pricing	Contact Us
50.00	41.87	50.00	UV-VIS (250-700nm)	Fused Silica	#26-608	€325,48 Volume Pricing	Contact Us
50.00	41.87	50.00	VIS 0° (425-675nm)	Fused Silica	#26-614	€330,63 Volume Pricing	5 In Stock
50.00	41.87	50.00	VIS-NIR (400-1000nm)	Fused Silica	#26-620	€330,63 Volume Pricing	1 In Stock
50.00	97.13	100.00	Uncoated	Fused Silica	#22-427	€299,73 Volume Pricing	Contact Us
50.00	97.13	100.00	UV-AR (250-425nm)	Fused Silica	#26-603	€330,63 Volume Pricing	Contact Us
50.00	97.13	100.00	UV-VIS (250-700nm)	Fused Silica	#26-609	€325,48 Volume Pricing	3 In Stock
50.00	97.13	100.00	VIS 0° (425-675nm)	Fused Silica	#26-615	€330,63 Volume Pricing	3 In Stock
50.00	97.13	100.00	VIS-NIR (400-1000nm)	Fused Silica	#26-621	€330,63 Volume Pricing	Contact Us
50.00	148.00	150.00	Uncoated	Fused Silica	#22-428	€299,73 Volume Pricing	10 In Stock

50.00	148.00	150.00	UV-AR (250-425nm)	Fused Silica	#26-604	€330,63 Volume Pricing	3 In Stock
50.00	148.00	150.00	UV-VIS (250-700nm)	Fused Silica	#26-610	€325,48 Volume Pricing	4 In Stock
50.00	148.00	150.00	VIS 0° (425-675nm)	Fused Silica	#26-616	€330,63 Volume Pricing	5 In Stock
50.00	148.00	150.00	VIS-NIR (400-1000nm)	Fused Silica	#26-622	€330,63 Volume Pricing	4 In Stock
50.00	198.39	200.00	Uncoated	Fused Silica	#22-429	€299,73 Volume Pricing	3 In Stock
50.00	198.39	200.00	UV-AR (250-425nm)	Fused Silica	#26-605	€330,63 Volume Pricing	2 In Stock
50.00	198.39	200.00	UV-VIS (250-700nm)	Fused Silica	#26-611	€325,48 Volume Pricing	2 In Stock
50.00	198.39	200.00	VIS 0° (425-675nm)	Fused Silica	#26-617	€330,63 Volume Pricing	5 In Stock
50.00	198.39	200.00	VIS-NIR (400-1000nm)	Fused Silica	#26-623	€330,63 Volume Pricing	1 In Stock



Copyright 2023 | Edmund Optics, Ltd Unit 1, Opus Avenue, Nether Poppleton, York, YO26 6BL, UK
 Phone: 1-800-363-1992 :
www.edmundoptics.com