


[All Products](#) / [Optics](#) / [Optical Lenses](#) / [Cylinder Lenses](#) / [Illumination Grade Cylinder Lenses](#)

TECHSPEC®

Illumination Grade PCX Cylinder Lenses

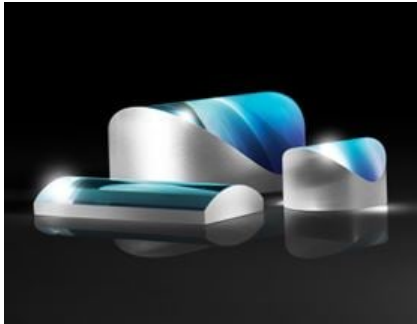


- N-BK7 Substrate for Broadband Performance
- Cost-Effective for OEM Integration
- Multiple Coating Options Available

Common Specifications

Physical & Mechanical Properties



Dimensional Tolerance (mm):	+0.0/-0.2
Optical Properties	
Focal Length Tolerance (%):	±3
Surface Quality:	60-40

Technical Information

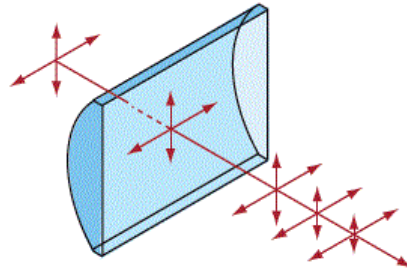

PCX Rectangular

Circular And Rectangular Cylinder Lenses

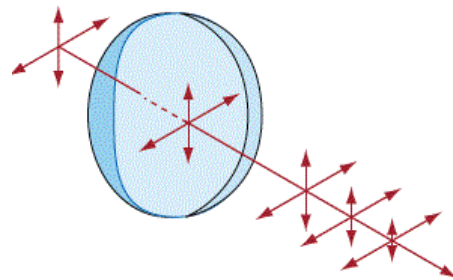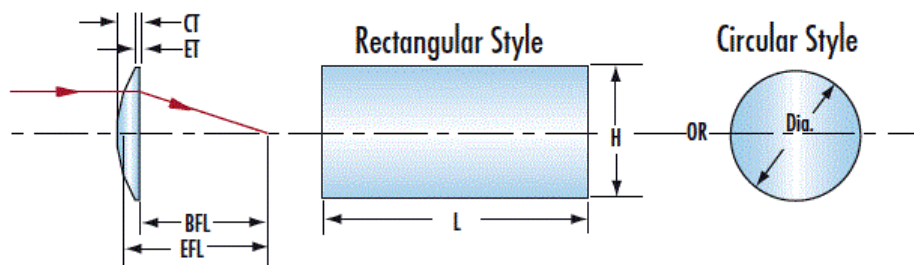

PCX Circular

Products

Dia. (mm)	Dimensions (mm)	EFL (mm)	Substrate	Coating	Stock Number	Price	Buy
5.00	-	8.00	N-BK7	Uncoated	#45-981	€115,36 Volume Pricing	20+ In Stock
5.00	-	8.00	N-BK7	MgF ₂ (400-700nm)	#47-760	€125,66 Volume Pricing	20+ In Stock
#45-982 Clearance							
							
Clearance							
Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.							
5.00	-	30.00	N-BK7	Uncoated		€56,60	14 In Stock

[#47-955 Clearance](#)



Clearance

Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.

5.00	-	30.00	N-BK7	VIS-NIR (400-1000nm)		€71,02	14 In Stock
------	---	-------	-----------------------	----------------------	--	--------	-------------

-	5.0 x 10.0	8.00	N-BK7	Uncoated	#43-856	€115,36 Volume Pricing	20+ In Stock
-	5.0 x 10.0	8.00	N-BK7	MgF ₂ (400-700nm)	#47-763	€125,66 Volume Pricing	4 In Stock
-	5.0 x 10.0	20.00	N-BK7	Uncoated	#43-857	€115,36 Volume Pricing	15 In Stock
-	5.0 x 10.0	20.00	N-BK7	MgF ₂ (400-700nm)	#47-764	€125,66 Volume Pricing	4 In Stock
-	5.0 x 10.0	20.00	N-BK7	VIS 0° (425-675nm)	#69-693	€132,87 Volume Pricing	4 In Stock
-	5.0 x 10.0	20.00	N-BK7	VIS-NIR (400-1000nm)	#47-958	€132,87 Volume Pricing	1 In Stock
-	5.0 x 10.0	20.00	N-BK7	NIR I (600-1050nm)	#69-704	€132,87 Volume Pricing	2 In Stock
-	5.0 x 10.0	50.00	N-BK7	Uncoated	#43-859	€115,36 Volume Pricing	10 In Stock
-	5.0 x 10.0	50.00	N-BK7	MgF ₂ (400-700nm)	#47-766	€125,66 Volume Pricing	14 In Stock

-	5.0 x 10.0	50.00	N-BK7	VIS 0° (425-675nm)	#69-695	€132,87 Volume Pricing	20+ In Stock
-	5.0 x 10.0	50.00	N-BK7	VIS-NIR (400-1000nm)	#47-960	€132,87 Volume Pricing	11 In Stock
-	5.0 x 10.0	50.00	N-BK7	NIR I (600-1050nm)	#69-706	€132,87 Volume Pricing	Contact Us
6.00	-	6.00	N-SF11	Uncoated	#68-024	€63,35 Volume Pricing	20+ In Stock
6.00	-	6.00	N-SF11	MgF ₂ (400-700nm)	#68-038	€74,68 Volume Pricing	20+ In Stock
6.00	-	9.00	N-SF11	Uncoated	#68-025	€63,35 Volume Pricing	20+ In Stock
6.00	-	9.00	N-SF11	MgF ₂ (400-700nm)	#68-039	€74,68 Volume Pricing	12 In Stock
6.00	-	12.00	N-BK7	Uncoated	#68-026	€63,35 Volume Pricing	20+ In Stock
6.00	-	12.00	N-BK7	MgF ₂ (400-700nm)	#68-040	€74,68 Volume Pricing	Contact Us
6.00	-	12.00	N-BK7	VIS 0° (425-675nm)	#69-714	€84,46 Volume Pricing	14 In Stock
6.00	-	12.00	N-BK7	VIS-NIR (400-1000nm)	#69-766	€84,46 Volume Pricing	5 In Stock
6.00	-	12.00	N-BK7	NIR I (600-1050nm)	#69-740	€84,46 Volume Pricing	5 In Stock
6.00	-	18.00	N-BK7	Uncoated	#68-027	€63,35 Volume Pricing	13 In Stock
6.00	-	18.00	N-BK7	MgF ₂ (400-700nm)	#68-041	€74,68 Volume Pricing	20+ In Stock
6.00	-	18.00	N-BK7	VIS 0° (425-675nm)	#69-715	€84,46 Volume Pricing	20+ In Stock
6.00	-	18.00	N-BK7	VIS-NIR (400-1000nm)	#69-767	€84,46 Volume Pricing	Contact Us

6.00	-	18.00	N-BK7	NIR I (600-1050nm)	#69-741	€84,46 Volume Pricing	4 In Stock
6.00	-	24.00	N-BK7	Uncoated	#68-028	€63,35 Volume Pricing	20+ In Stock
6.00	-	24.00	N-BK7	MgF ₂ (400-700nm)	#68-042	€74,68 Volume Pricing	4 In Stock
6.00	-	24.00	N-BK7	VIS 0° (425-675nm)	#69-716	€84,46 Volume Pricing	2 In Stock
6.00	-	24.00	N-BK7	VIS-NIR (400-1000nm)	#69-768	€84,46 Volume Pricing	Contact Us
6.00	-	24.00	N-BK7	NIR I (600-1050nm)	#69-742	€84,46 Volume Pricing	20+ In Stock
-	10.0 x 10.0	25.00	N-BK7	VIS 0° (425-675nm)	#25-484	€87,04 Volume Pricing	2 In Stock
-	10.0 x 10.0	25.00	N-BK7	NIR I (600-1050nm)	#25-485	€87,04 Volume Pricing	Contact Us
10.00	-	15.00	N-BK7	Uncoated	#47-754	€126,69 Volume Pricing	4 In Stock
10.00	-	15.00	N-BK7	MgF ₂ (400-700nm)	#47-767	€138,02 Volume Pricing	13 In Stock

[#69-696 Clearance](#)



Clearance

Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.

10.00	-	20.00	N-BK7	VIS 0° (425-675nm)		€71,02	8 In Stock
-------	---	-------	-----------------------	-----------------------	--	--------	------------

10.00	-	30.00	N-BK7	Uncoated	#47-756	€126,69 Volume Pricing	20+ In Stock
-------	---	-------	-----------------------	----------	-------------------------	---	--------------

10.00	-	30.00	N-BK7	MgF ₂ (400-700nm)	#47-769	€138,02 Volume Pricing	5 In Stock
-------	---	-------	-----------------------	---------------------------------	-------------------------	---	------------

10.00	-	30.00	N-BK7	VIS 0° (425-675nm)	#69-697	€145,23 Volume Pricing	1 In Stock
-------	---	-------	-----------------------	-----------------------	-------------------------	---	------------

10.00	-	30.00	N-BK7	VIS-NIR (400-1000nm)	#47-963	€145,23 Volume Pricing	2 In Stock
-------	---	-------	-----------------------	-------------------------	-------------------------	---	------------

10.00	-	30.00	N-BK7	NIR I (600-1050nm)	#69-708	€145,23 Volume Pricing	7 In Stock
-------	---	-------	-----------------------	-----------------------	-------------------------	---	------------

10.00	-	50.00	N-BK7	Uncoated	#47-757	€126,69 Volume Pricing	20+ In Stock
-------	---	-------	-----------------------	----------	-------------------------	---	--------------

10.00	-	50.00	N-BK7	MgF ₂ (400-700nm)	#47-770	€138,02 Volume Pricing	3 In Stock
-------	---	-------	-----------------------	---------------------------------	-------------------------	---	------------

10.00	-	50.00	N-BK7	VIS 0° (425-675nm)	#69-698	€145,23 Volume Pricing	1 In Stock
-------	---	-------	-----------------------	-----------------------	-------------------------	---	------------

10.00	-	50.00	N-BK7	VIS-NIR (400-1000nm)	#47-964	€145,23 Volume Pricing	5 In Stock
-------	---	-------	-----------------------	-------------------------	-------------------------	---	------------

10.00	-	50.00	N-BK7	NIR I (600-1050nm)	#69-709	€145,23 Volume Pricing	Contact Us
-	10.0 x 10.0	25.00	N-BK7	Uncoated	#25-483	€65,92 Volume Pricing	20+ In Stock
-	10.0 x 20.0	25.00	N-BK7	Uncoated	#25-486	€80,86 Volume Pricing	20+ In Stock
-	10.0 x 20.0	25.00	N-BK7	VIS 0° (425-675nm)	#25-487	€101,97 Volume Pricing	2 In Stock
-	10.0 x 20.0	25.00	N-BK7	NIR I (600-1050nm)	#25-488	€101,97 Volume Pricing	5 In Stock

[#47-775 Clearance](#)



Clearance

Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.

12.50	-	12.50	N-BK7	Uncoated	#46-193	€65,92 Volume Pricing	20+ In Stock
12.50	-	12.50	N-BK7	MgF ₂ (400-700nm)	#48-352	€75,71 Volume Pricing	20+ In Stock
12.50	-	25.00	N-BK7	Uncoated	#46-194	€65,92 Volume Pricing	20+ In Stock
12.50	-	25.00	N-BK7	MgF ₂ (400-700nm)	#48-353	€75,71 Volume Pricing	20+ In Stock
12.50	-	25.00	N-BK7	VIS 0° (425-675nm)	#69-717	€87,04 Volume Pricing	20+ In Stock

12.50	-	25.00	N-BK7	VIS-NIR (400-1000nm)	#69-769	€87,04 Volume Pricing	3 In Stock
12.50	-	25.00	N-BK7	NIR I (600-1050nm)	#69-743	€87,04 Volume Pricing	1 In Stock
12.50	-	50.00	N-BK7	Uncoated	#46-195	€65,92 Volume Pricing	20+ In Stock
12.50	-	50.00	N-BK7	MgF ₂ (400-700nm)	#48-354	€75,71 Volume Pricing	20+ In Stock
12.50	-	50.00	N-BK7	VIS 0° (425-675nm)	#69-718	€87,04 Volume Pricing	1 In Stock
12.50	-	50.00	N-BK7	VIS-NIR (400-1000nm)	#69-770	€87,04 Volume Pricing	20+ In Stock
12.50	-	50.00	N-BK7	NIR I (600-1050nm)	#69-744	€87,04 Volume Pricing	Contact Us
12.50	-	75.00	N-BK7	Uncoated	#47-742	€65,92 Volume Pricing	20+ In Stock
12.50	-	75.00	N-BK7	MgF ₂ (400-700nm)	#48-355	€75,71 Volume Pricing	20+ In Stock
12.50	-	75.00	N-BK7	VIS 0° (425-675nm)	#69-719	€87,04 Volume Pricing	15 In Stock
12.50	-	75.00	N-BK7	VIS-NIR (400-1000nm)	#69-771	€87,04 Volume Pricing	Contact Us
12.50	-	75.00	N-BK7	NIR I (600-1050nm)	#69-745	€87,04 Volume Pricing	Contact Us
12.50	-	100.00	N-BK7	Uncoated	#47-743	€65,92 Volume Pricing	20+ In Stock
12.50	-	100.00	N-BK7	MgF ₂ (400-700nm)	#48-356	€75,71 Volume Pricing	20+ In Stock
12.50	-	100.00	N-BK7	VIS 0° (425-675nm)	#69-720	€87,04 Volume Pricing	9 In Stock
-	12.5 x 25.0	12.50	N-SF11	Uncoated	#68-029	€65,92 Volume Pricing	20+ In Stock

-	12.5 x 25.0	12.50	N-SF11	MgF ₂ (400-700nm)	#68-043	€75,71 Volume Pricing	5 In Stock
-	12.5 x 25.0	15.00	N-SF11	Uncoated	#68-030	€65,92 Volume Pricing	14 In Stock
-	12.5 x 25.0	15.00	N-SF11	MgF ₂ (400-700nm)	#68-044	€75,71 Volume Pricing	6 In Stock
-	12.5 x 25.0	20.00	N-BK7	Uncoated	#68-031	€65,92 Volume Pricing	4 In Stock
-	12.5 x 25.0	20.00	N-BK7	MgF ₂ (400-700nm)	#68-045	€75,71 Volume Pricing	1 In Stock
-	12.5 x 25.0	20.00	N-BK7	VIS 0° (425-675nm)	#69-721	€87,04 Volume Pricing	Contact Us
-	12.5 x 25.0	20.00	N-BK7	VIS-NIR (400-1000nm)	#69-773	€87,04 Volume Pricing	4 In Stock
-	12.5 x 25.0	20.00	N-BK7	NIR I (600-1050nm)	#69-747	€87,04 Volume Pricing	4 In Stock
-	12.5 x 25.0	25.00	N-BK7	Uncoated	#68-032	€65,92 Volume Pricing	20+ In Stock
-	12.5 x 25.0	25.00	N-BK7	MgF ₂ (400-700nm)	#68-046	€75,71 Volume Pricing	20+ In Stock
-	12.5 x 25.0	25.00	N-BK7	VIS 0° (425-675nm)	#69-722	€87,04 Volume Pricing	10 In Stock
-	12.5 x 25.0	25.00	N-BK7	VIS-NIR (400-1000nm)	#69-774	€87,04 Volume Pricing	6 In Stock
-	12.5 x 25.0	25.00	N-BK7	NIR I (600-1050nm)	#69-748	€87,04 Volume Pricing	8 In Stock
-	12.5 x 25.0	50.00	N-BK7	Uncoated	#68-033	€65,92 Volume Pricing	20+ In Stock
-	12.5 x 25.0	50.00	N-BK7	MgF ₂ (400-700nm)	#68-047	€75,71 Volume Pricing	5 In Stock
-	12.5 x 25.0	50.00	N-BK7	VIS 0° (425-675nm)	#69-723	€87,04 Volume Pricing	20+ In Stock

-	12.5 x 25.0	50.00	N-BK7	VIS-NIR (400-1000nm)	#69-775	€87,04 Volume Pricing	5 In Stock
-	12.5 x 25.0	50.00	N-BK7	NIR I (600-1050nm)	#69-749	€87,04 Volume Pricing	4 In Stock
-	12.5 x 25.0	75.00	N-BK7	Uncoated	#68-034	€65,92 Volume Pricing	10 In Stock
-	12.5 x 25.0	75.00	N-BK7	MgF ₂ (400-700nm)	#68-048	€75,71 Volume Pricing	8 In Stock
-	12.5 x 25.0	75.00	N-BK7	VIS 0° (425-675nm)	#69-724	€87,04 Volume Pricing	20+ In Stock
-	12.5 x 25.0	75.00	N-BK7	VIS-NIR (400-1000nm)	#69-776	€87,04 Volume Pricing	13 In Stock
-	12.5 x 25.0	75.00	N-BK7	NIR I (600-1050nm)	#69-750	€87,04 Volume Pricing	3 In Stock
-	12.5 x 25.0	100.00	N-BK7	Uncoated	#68-035	€65,92 Volume Pricing	20+ In Stock
-	12.5 x 25.0	100.00	N-BK7	MgF ₂ (400-700nm)	#68-049	€75,71 Volume Pricing	5 In Stock
-	12.5 x 25.0	100.00	N-BK7	VIS 0° (425-675nm)	#69-725	€87,04 Volume Pricing	5 In Stock
-	12.5 x 25.0	100.00	N-BK7	VIS-NIR (400-1000nm)	#69-777	€87,04 Volume Pricing	20+ In Stock
-	12.5 x 25.0	100.00	N-BK7	NIR I (600-1050nm)	#69-751	€87,04 Volume Pricing	3 In Stock
-	12.5 x 25.0	150.00	N-BK7	Uncoated	#68-037	€65,92 Volume Pricing	20+ In Stock
-	12.5 x 25.0	150.00	N-BK7	MgF ₂ (400-700nm)	#68-051	€75,71 Volume Pricing	5 In Stock
-	12.5 x 25.0	150.00	N-BK7	VIS 0° (425-675nm)	#69-726	€87,04 Volume Pricing	Contact Us
-	12.5 x 25.0	150.00	N-BK7	VIS-NIR (400-1000nm)	#69-778	€87,04 Volume Pricing	9 In Stock

-	12.5 x 25.0	150.00	N-BK7	NIR I (600-1050nm)	#69-752	€87,04 Volume Pricing	3 In Stock
-	12.7 x 12.7	12.50	N-BK7	Uncoated	#35-020	€65,92 Volume Pricing	20+ In Stock
-	12.7 x 12.7	12.50	N-BK7	VIS 0° (425-675nm)	#36-208	€87,04 Volume Pricing	Contact Us
-	12.7 x 12.7	12.50	N-BK7	VIS-NIR (400-1000nm)	#36-217	€87,04 Volume Pricing	1 In Stock
-	12.7 x 12.7	12.50	N-BK7	NIR I (600-1050nm)	#36-227	€87,04 Volume Pricing	1 In Stock
-	12.7 x 12.7	25.00	N-BK7	Uncoated	#35-021	€65,92 Volume Pricing	20+ In Stock
-	12.7 x 12.7	25.00	N-BK7	VIS 0° (425-675nm)	#36-209	€87,04 Volume Pricing	2 In Stock
-	12.7 x 12.7	25.00	N-BK7	VIS-NIR (400-1000nm)	#36-218	€87,04 Volume Pricing	Contact Us
-	12.7 x 12.7	25.00	N-BK7	NIR I (600-1050nm)	#36-228	€87,04 Volume Pricing	2 In Stock
-	12.7 x 12.7	100.00	N-BK7	Uncoated	#35-022	€65,92 Volume Pricing	20+ In Stock
-	12.7 x 12.7	100.00	N-BK7	VIS 0° (425-675nm)	#36-210	€87,04 Volume Pricing	Contact Us
-	12.7 x 12.7	100.00	N-BK7	VIS-NIR (400-1000nm)	#36-219	€87,04 Volume Pricing	20+ In Stock
-	12.7 x 12.7	100.00	N-BK7	NIR I (600-1050nm)	#36-229	€87,04 Volume Pricing	5 In Stock
-	12.7 x 12.7	150.00	N-BK7	Uncoated	#35-023	€65,92 Volume Pricing	20+ In Stock
-	12.7 x 12.7	150.00	N-BK7	VIS 0° (425-675nm)	#36-211	€87,04 Volume Pricing	5 In Stock
-	12.7 x 12.7	150.00	N-BK7	VIS-NIR (400-1000nm)	#36-220	€87,04 Volume Pricing	3 In Stock

-	12.7 x 12.7	150.00	N-BK7	NIR I (600-1050nm)	#36-230	€87,04 Volume Pricing	4 In Stock
-	20.0 x 20.0	25.00	N-BK7	Uncoated	#25-489	€98,88 Volume Pricing	20+ In Stock
-	20.0 x 20.0	25.00	N-BK7	VIS 0° (425-675nm)	#25-490	€119,48 Volume Pricing	5 In Stock
-	20.0 x 20.0	25.00	N-BK7	NIR I (600-1050nm)	#25-491	€119,48 Volume Pricing	5 In Stock
-	20.0 x 20.0	50.00	N-BK7	Uncoated	#25-495	€98,88 Volume Pricing	5 In Stock
-	20.0 x 20.0	50.00	N-BK7	VIS 0° (425-675nm)	#25-496	€119,48 Volume Pricing	5 In Stock
-	20.0 x 20.0	50.00	N-BK7	NIR I (600-1050nm)	#25-497	€119,48 Volume Pricing	5 In Stock
-	20.0 x 40.0	25.00	N-BK7	Uncoated	#25-492	€121,54 Volume Pricing	14 In Stock
-	20.0 x 40.0	25.00	N-BK7	VIS 0° (425-675nm)	#25-493	€143,17 Volume Pricing	5 In Stock
-	20.0 x 40.0	25.00	N-BK7	NIR I (600-1050nm)	#25-494	€143,17 Volume Pricing	4 In Stock
-	20.0 x 40.0	50.00	N-BK7	Uncoated	#25-498	€121,54 Volume Pricing	20+ In Stock
-	20.0 x 40.0	50.00	N-BK7	VIS 0° (425-675nm)	#25-499	€143,17 Volume Pricing	4 In Stock
-	20.0 x 40.0	50.00	N-BK7	NIR I (600-1050nm)	#25-500	€143,17 Volume Pricing	2 In Stock
25.00	-	25.00	N-BK7	Uncoated	#46-015	€74,16 Volume Pricing	20+ In Stock
25.00	-	25.00	N-BK7	MgF ₂ (400-700nm)	#48-357	€83,95 Volume Pricing	16 In Stock
25.00	-	50.00	N-BK7	Uncoated	#46-016	€74,16 Volume Pricing	20+ In Stock
25.00	-	50.00	N-BK7	MgF ₂ (400-700nm)	#48-358	€83,95 Volume Pricing	20+ In Stock

25.00	-	50.00	N-BK7	VIS 0° (425-675nm)	#69-727	€93,22 Volume Pricing	20+ In Stock
25.00	-	50.00	N-BK7	VIS-NIR (400-1000nm)	#69-779	€93,22 Volume Pricing	3 In Stock
25.00	-	50.00	N-BK7	NIR I (600-1050nm)	#69-753	€93,22 Volume Pricing	20+ In Stock
25.00	-	75.00	N-BK7	Uncoated	#46-017	€74,16 Volume Pricing	20+ In Stock
25.00	-	75.00	N-BK7	MgF ₂ (400-700nm)	#48-359	€83,95 Volume Pricing	7 In Stock
25.00	-	75.00	N-BK7	VIS 0° (425-675nm)	#69-728	€93,22 Volume Pricing	5 In Stock
25.00	-	75.00	N-BK7	VIS-NIR (400-1000nm)	#69-780	€83,95 Volume Pricing	1 In Stock
25.00	-	75.00	N-BK7	NIR I (600-1050nm)	#69-754	€93,22 Volume Pricing	2 In Stock
25.00	-	100.00	N-BK7	Uncoated	#46-018	€74,16 Volume Pricing	20+ In Stock
25.00	-	100.00	N-BK7	MgF ₂ (400-700nm)	#48-360	€83,95 Volume Pricing	11 In Stock
25.00	-	100.00	N-BK7	VIS 0° (425-675nm)	#69-729	€93,22 Volume Pricing	6 In Stock
25.00	-	100.00	N-BK7	VIS-NIR (400-1000nm)	#69-781	€93,22 Volume Pricing	Contact Us
25.00	-	100.00	N-BK7	NIR I (600-1050nm)	#69-755	€93,22 Volume Pricing	Contact Us
25.00	-	125.00	N-BK7	Uncoated	#47-744	€74,16 Volume Pricing	20+ In Stock
25.00	-	125.00	N-BK7	MgF ₂ (400-700nm)	#48-361	€83,95 Volume Pricing	8 In Stock
25.00	-	125.00	N-BK7	VIS 0° (425-675nm)	#69-730	€93,22 Volume Pricing	6 In Stock

25.00	-	125.00	N-BK7	VIS-NIR (400-1000nm)	#69-782	€93,22 Volume Pricing	5 In Stock
25.00	-	125.00	N-BK7	NIR I (600-1050nm)	#69-756	€93,22 Volume Pricing	7 In Stock
25.00	-	150.00	N-BK7	Uncoated	#46-019	€74,16 Volume Pricing	20+ In Stock
25.00	-	150.00	N-BK7	MgF ₂ (400-700nm)	#48-362	€83,95 Volume Pricing	20+ In Stock
25.00	-	150.00	N-BK7	VIS 0° (425-675nm)	#69-731	€93,22 Volume Pricing	5 In Stock
25.00	-	150.00	N-BK7	VIS-NIR (400-1000nm)	#69-783	€93,22 Volume Pricing	3 In Stock
25.00	-	150.00	N-BK7	NIR I (600-1050nm)	#69-757	€93,22 Volume Pricing	7 In Stock
-	25.0 x 50.0	25.00	N-BK7	Uncoated	#46-020	€116,39 Volume Pricing	20+ In Stock
-	25.0 x 50.0	25.00	N-BK7	MgF ₂ (400-700nm)	#48-363	€127,72 Volume Pricing	11 In Stock
-	25.0 x 50.0	50.00	N-BK7	Uncoated	#46-021	€116,39 Volume Pricing	20+ In Stock
-	25.0 x 50.0	50.00	N-BK7	MgF ₂ (400-700nm)	#48-364	€127,72 Volume Pricing	20+ In Stock
-	25.0 x 50.0	50.00	N-BK7	VIS 0° (425-675nm)	#69-732	€136,99 Volume Pricing	2 In Stock
-	25.0 x 50.0	50.00	N-BK7	VIS-NIR (400-1000nm)	#69-784	€136,99 Volume Pricing	2 In Stock
-	25.0 x 50.0	50.00	N-BK7	NIR I (600-1050nm)	#69-758	€136,99 Volume Pricing	2 In Stock
-	25.0 x 50.0	75.00	N-BK7	Uncoated	#46-022	€116,39 Volume Pricing	2 In Stock
-	25.0 x 50.0	75.00	N-BK7	MgF ₂ (400-700nm)	#48-365	€127,72 Volume Pricing	1 In Stock

-	25.0 x 50.0	75.00	N-BK7	VIS 0° (425-675nm)	#69-733	€136,99 Volume Pricing	6 In Stock
-	25.0 x 50.0	75.00	N-BK7	VIS-NIR (400-1000nm)	#69-785	€136,99 Volume Pricing	1 In Stock
-	25.0 x 50.0	75.00	N-BK7	NIR I (600-1050nm)	#69-759	€136,99 Volume Pricing	20+ In Stock
-	25.0 x 50.0	100.00	N-BK7	Uncoated	#46-023	€116,39 Volume Pricing	2 In Stock
-	25.0 x 50.0	100.00	N-BK7	MgF ₂ (400-700nm)	#48-366	€127,72 Volume Pricing	3 In Stock
-	25.0 x 50.0	100.00	N-BK7	VIS 0° (425-675nm)	#69-734	€136,99 Volume Pricing	4 In Stock
-	25.0 x 50.0	100.00	N-BK7	VIS-NIR (400-1000nm)	#69-786	€136,99 Volume Pricing	3 In Stock
-	25.0 x 50.0	100.00	N-BK7	NIR I (600-1050nm)	#69-760	€136,99 Volume Pricing	8 In Stock
-	25.0 x 50.0	150.00	N-BK7	Uncoated	#46-024	€116,39 Volume Pricing	2 In Stock
-	25.0 x 50.0	150.00	N-BK7	MgF ₂ (400-700nm)	#48-367	€127,72 Volume Pricing	5 In Stock
-	25.0 x 50.0	150.00	N-BK7	VIS 0° (425-675nm)	#69-735	€136,99 Volume Pricing	5 In Stock
-	25.0 x 50.0	150.00	N-BK7	VIS-NIR (400-1000nm)	#69-787	€136,99 Volume Pricing	1 In Stock
-	25.0 x 50.0	150.00	N-BK7	NIR I (600-1050nm)	#69-761	€136,99 Volume Pricing	1 In Stock
-	25.4 x 25.4	50.00	N-BK7	Uncoated	#35-024	€74,16 Volume Pricing	20+ In Stock
-	25.4 x 25.4	50.00	N-BK7	VIS 0° (425-675nm)	#36-212	€93,22 Volume Pricing	2 In Stock
-	25.4 x 25.4	50.00	N-BK7	VIS-NIR (400-1000nm)	#36-222	€93,22 Volume Pricing	3 In Stock

-	25.4 x 25.4	50.00	N-BK7	NIR I (600-1050nm)	#36-231	€93,22 Volume Pricing	1 In Stock
-	25.4 x 25.4	100.00	N-BK7	Uncoated	#35-025	€74,16 Volume Pricing	20+ In Stock
-	25.4 x 25.4	100.00	N-BK7	VIS 0° (425-675nm)	#36-213	€93,22 Volume Pricing	6 In Stock
-	25.4 x 25.4	100.00	N-BK7	VIS-NIR (400-1000nm)	#36-223	€93,22 Volume Pricing	3 In Stock
-	25.4 x 25.4	100.00	N-BK7	NIR I (600-1050nm)	#36-232	€93,22 Volume Pricing	3 In Stock
-	25.4 x 25.4	150.00	N-BK7	Uncoated	#35-026	€74,16 Volume Pricing	20+ In Stock
-	25.4 x 25.4	150.00	N-BK7	VIS 0° (425-675nm)	#36-214	€93,22 Volume Pricing	1 In Stock
-	25.4 x 25.4	150.00	N-BK7	VIS-NIR (400-1000nm)	#36-224	€93,22 Volume Pricing	2 In Stock
-	25.4 x 25.4	150.00	N-BK7	NIR I (600-1050nm)	#36-233	€93,22 Volume Pricing	5 In Stock
-	25.4 x 25.4	200.00	N-BK7	Uncoated	#35-027	€74,16 Volume Pricing	20+ In Stock
-	25.4 x 25.4	200.00	N-BK7	VIS 0° (425-675nm)	#36-215	€93,22 Volume Pricing	Contact Us
-	25.4 x 25.4	200.00	N-BK7	VIS-NIR (400-1000nm)	#36-225	€93,22 Volume Pricing	3 In Stock
-	25.4 x 25.4	200.00	N-BK7	NIR I (600-1050nm)	#36-234	€93,22 Volume Pricing	5 In Stock
-	25.4 x 25.4	250.00	N-BK7	Uncoated	#35-028	€74,16 Volume Pricing	20+ In Stock
-	25.4 x 25.4	250.00	N-BK7	VIS 0° (425-675nm)	#36-216	€93,22 Volume Pricing	2 In Stock
-	25.4 x 25.4	250.00	N-BK7	VIS-NIR (400-1000nm)	#36-226	€93,22 Volume Pricing	11 In Stock

-	25.4 x 25.4	250.00	N-BK7	NIR I (600-1050nm)	#36-235	€93,22 Volume Pricing	2 In Stock
-	30.0 x 30.0	50.00	N-BK7	Uncoated	#25-501	€138,02 Volume Pricing	20+ In Stock
-	30.0 x 30.0	50.00	N-BK7	VIS 0° (425-675nm)	#25-502	€159,65 Volume Pricing	4 In Stock
-	30.0 x 30.0	50.00	N-BK7	NIR I (600-1050nm)	#25-503	€159,65 Volume Pricing	11 In Stock
-	30.0 x 30.0	100.00	N-BK7	Uncoated	#25-504	€138,02 Volume Pricing	6 In Stock
-	30.0 x 30.0	100.00	N-BK7	NIR I (600-1050nm)	#25-506	€159,65 Volume Pricing	5 In Stock
-	30.0 x 30.0	100.00	N-BK7	VIS 0° (425-675nm)	#25-505	€159,65 Volume Pricing	5 In Stock
-	50.0 x 25.0	75.00	N-BK7	Uncoated	#46-198	€116,39 Volume Pricing	20+ In Stock
-	50.0 x 25.0	75.00	N-BK7	MgF ₂ (400-700nm)	#48-368	€127,72 Volume Pricing	8 In Stock
-	50.0 x 25.0	75.00	N-BK7	VIS 0° (425-675nm)	#69-736	€136,99 Volume Pricing	1 In Stock
-	50.0 x 25.0	75.00	N-BK7	VIS-NIR (400-1000nm)	#69-788	€136,99 Volume Pricing	2 In Stock
-	50.0 x 25.0	75.00	N-BK7	NIR I (600-1050nm)	#69-762	€136,99 Volume Pricing	5 In Stock
-	50.0 x 25.0	100.00	N-BK7	Uncoated	#46-199	€116,39 Volume Pricing	20+ In Stock
-	50.0 x 25.0	100.00	N-BK7	MgF ₂ (400-700nm)	#48-369	€127,72 Volume Pricing	2 In Stock
-	50.0 x 25.0	100.00	N-BK7	VIS 0° (425-675nm)	#69-737	€136,99 Volume Pricing	5 In Stock
-	50.0 x 25.0	100.00	N-BK7	VIS-NIR (400-1000nm)	#69-789	€136,99 Volume Pricing	3 In Stock

-	50.0 x 25.0	100.00	N-BK7	NIR I (600-1050nm)	#69-763	€136,99 Volume Pricing	3 In Stock
-	50.0 x 25.0	150.00	N-BK7	Uncoated	#46-200	€116,39 Volume Pricing	20+ In Stock
-	50.0 x 25.0	150.00	N-BK7	MgF ₂ (400-700nm)	#48-370	€127,72 Volume Pricing	Contact Us
-	50.0 x 25.0	150.00	N-BK7	VIS 0° (425-675nm)	#69-738	€136,99 Volume Pricing	3 In Stock
 Edmund optics worldwide							
				VIS-NIR (400-1000nm)	#69-790	€136,99 Volume Pricing	5 In Stock
Copyright 2023 Edmund Optics, Ltd Unit 1, Opus Avenue, Nether Poppleton, York, YO26 6BL, UK Phone: 1-800-363-1992 : www.edmundoptics.com							
	50.0 x 25.0	150.00	N-BK7	NIR I (600-1050nm)	#69-764	€136,99 Volume Pricing	3 In Stock