

[All Products](#) / [Microscopy](#) / [Infinity Corrected Objectives](#)

# Nikon CFI Super Fluor Objectives

See More by [Nikon](#)

- Superior UV Transmission
- High Numerical Aperture Designs
- Feature Low Auto-Fluorescence Materials



## Common Specifications

### General

Compatible Tube Lens Focal Length (mm):	Focal Length: 200mm	Manufacturer:	Nikon
--	---------------------	---------------	-------

### Optical Properties

Compatible Cover Glass Thickness (mm):	0.17	Field Number (mm):	22
---	------	--------------------	----


### Sensor

Maximum Sensor Format:	2/3"
------------------------	------


### Threading & Mounting

Mounting Threads:	M25 x 0.75
-------------------	------------

Technical Information

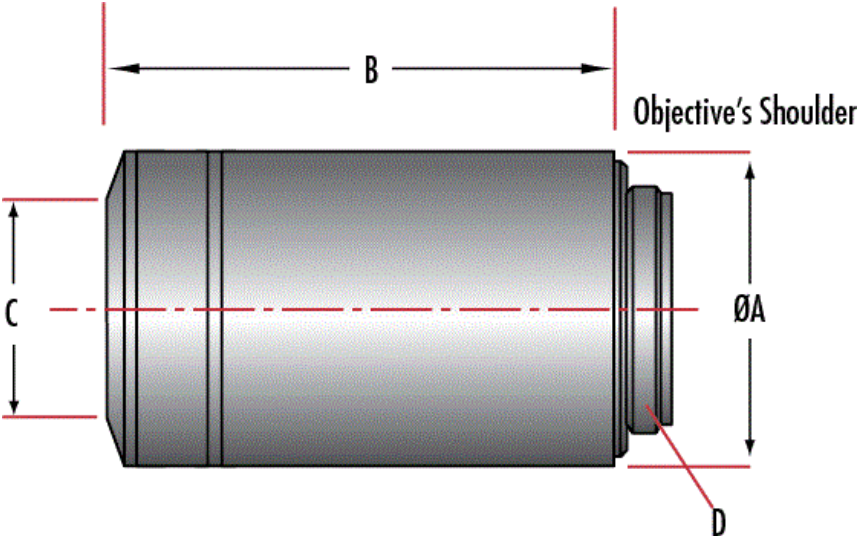

## Products

Magnification	NA	Field Number (mm)	Model Number	WD (mm)	Stock Number	Price	Buy
10X	0.50	22	MRF00101	1.2	<a href="#">#88-375</a>	€4.823,00	Contact Us
20X	0.75	22	MRF00201	1.0	<a href="#">#88-376</a>	€5.957,20	Contact Us
<a href="#">#75-346 New</a>							
 <p>New</p> <p>Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!</p>							
40X	1.3	22	MRF01401	0.19		€5.647,68	1 In Stock



Copyright 2023 | Edmund Optics, Ltd Unit 1, Opus Avenue, Nether Poppleton, York, YO26 6BL, UK  
 Phone: 1-800-363-1992 :  
[www.edmundoptics.com](http://www.edmundoptics.com)