

[All Products](#) / [Optics](#) / [SCHOTT Optical Components](#)

**SCHOTT Colored Glass Longpass Filters** See More by [SCHOTT Optical Components](#)





- 27 Standard SCHOTT Color Glass Types
- Cut-On Wavelengths in the UV, Visible, or NIR
- Standard Circular and Square Sizes with 1, 2, or 3mm Thickness


**Common Specifications**  
**Optical Properties**

|          |          |
|----------|----------|
| Coating: | Uncoated |
|----------|----------|

Technical Information

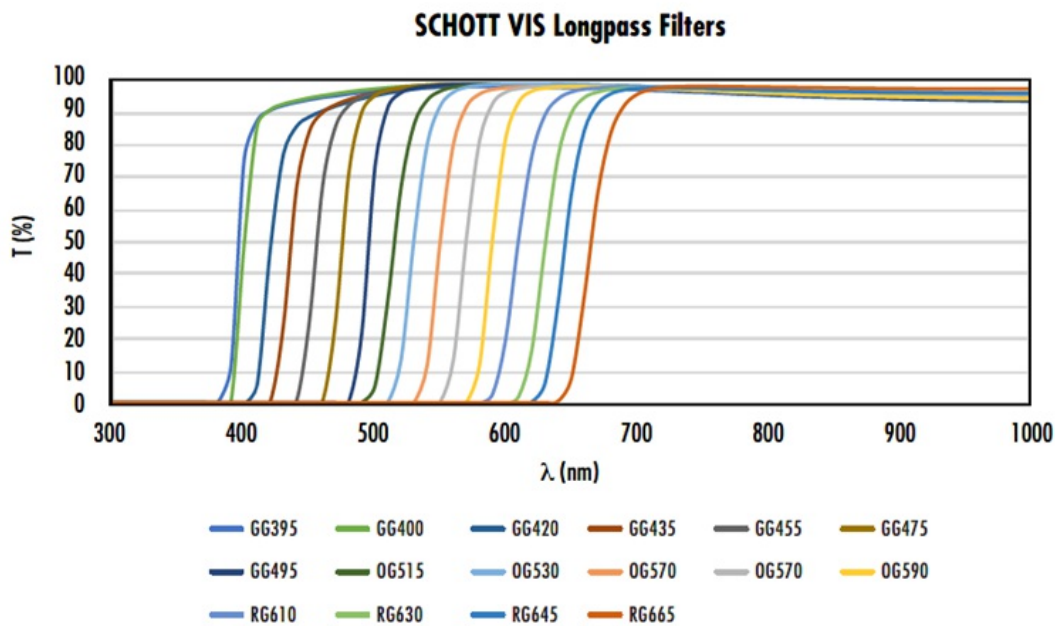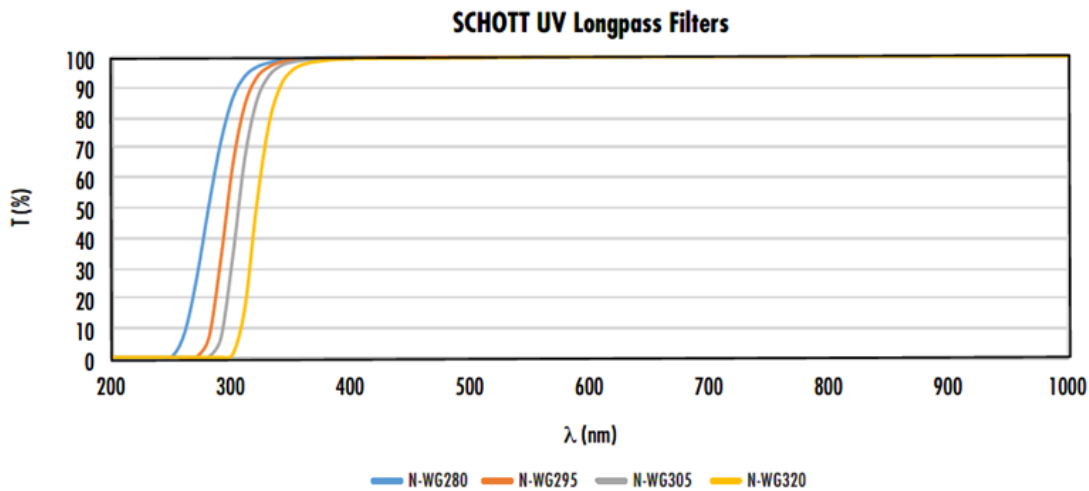

SCHOTT IR Longpass Filters

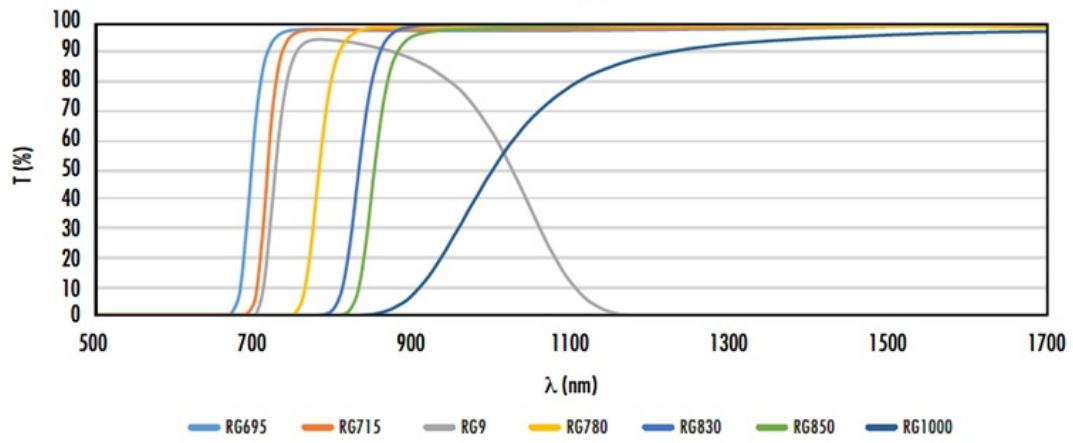

Products

| Dimensions<br>(mm)                                                                                                                       | Dia.<br>(mm) | Glass/Filter<br>Number | Cut-On<br>Wavelength<br>(nm) | Thickness<br>(mm) | Stock Number            | Price                                     | Buy          |
|------------------------------------------------------------------------------------------------------------------------------------------|--------------|------------------------|------------------------------|-------------------|-------------------------|-------------------------------------------|--------------|
| -                                                                                                                                        | 12.50        | SCHOTT<br>WG280        | 280.00                       | 1.00              | <a href="#">#16-403</a> | €37,00<br><a href="#">Volume Pricing</a>  | 6 In Stock   |
| -                                                                                                                                        | 12.50        | SCHOTT<br>WG280        | 280.00                       | 2.00              | <a href="#">#16-430</a> | €37,00<br><a href="#">Volume Pricing</a>  | 7 In Stock   |
| -                                                                                                                                        | 12.50        | SCHOTT<br>WG280        | 285.00                       | 3.00              | <a href="#">#64-509</a> | €37,00<br><a href="#">Volume Pricing</a>  | 12 In Stock  |
| -                                                                                                                                        | 25.40        | SCHOTT<br>WG280        | 285.00                       | 3.00              | <a href="#">#64-510</a> | €46,00<br><a href="#">Volume Pricing</a>  | 5 In Stock   |
| -                                                                                                                                        | 50.00        | SCHOTT<br>WG280        | 285.00                       | 3.00              | <a href="#">#66-071</a> | €105,00<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 50.0 x 50.0                                                                                                                              | -            | SCHOTT<br>WG280        | 280.00                       | 1.00              | <a href="#">#14-460</a> | €92,50<br><a href="#">Volume Pricing</a>  | 12 In Stock  |
| 50.0 x 50.0                                                                                                                              | -            | SCHOTT<br>WG280        | 280.00                       | 2.00              | <a href="#">#14-461</a> | €92,50<br><a href="#">Volume Pricing</a>  | 8 In Stock   |
| 50.0 x 50.0                                                                                                                              | -            | SCHOTT<br>WG280        | 280.00                       | 3.00              | <a href="#">#14-462</a> | €92,50<br><a href="#">Volume Pricing</a>  | 20+ In Stock |
| <a href="#">#64-511 Clearance</a>                                                                                                        |              |                        |                              |                   |                         |                                           |              |
|                                                       |              |                        |                              |                   |                         |                                           |              |
| Clearance                                                                                                                                |              |                        |                              |                   |                         |                                           |              |
| Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products. |              |                        |                              |                   |                         |                                           |              |
| 50.8 x 50.8                                                                                                                              | -            | SCHOTT<br>WG280        | 285.00                       | 3.00              |                         | €59,50                                    | 3 In Stock   |
| -                                                                                                                                        | 12.50        | SCHOTT<br>WG295        | 295.00                       | 1.00              | <a href="#">#16-404</a> | €37,00<br><a href="#">Volume Pricing</a>  | 2 In Stock   |
| -                                                                                                                                        | 12.50        | SCHOTT<br>WG295        | 295.00                       | 2.00              | <a href="#">#16-431</a> | €37,00<br><a href="#">Volume Pricing</a>  | 6 In Stock   |

|             |       |                 |        |      |                         |                                           |              |
|-------------|-------|-----------------|--------|------|-------------------------|-------------------------------------------|--------------|
| -           | 12.50 | SCHOTT<br>WG295 | 300.00 | 3.00 | <a href="#">#46-416</a> | €37,00<br><a href="#">Volume Pricing</a>  | 2 In Stock   |
| -           | 25.40 | SCHOTT<br>WG295 | 300.00 | 3.00 | <a href="#">#46-417</a> | €46,00<br><a href="#">Volume Pricing</a>  | 20+ In Stock |
| -           | 50.00 | SCHOTT<br>WG295 | 300.00 | 3.00 | <a href="#">#66-072</a> | €105,00<br><a href="#">Volume Pricing</a> | 6 In Stock   |
| 50.0 x 50.0 | -     | SCHOTT<br>WG295 | 295.00 | 1.00 | <a href="#">#14-463</a> | €92,50<br><a href="#">Volume Pricing</a>  | 13 In Stock  |
| 50.0 x 50.0 | -     | SCHOTT<br>WG295 | 295.00 | 2.00 | <a href="#">#14-464</a> | €92,50<br><a href="#">Volume Pricing</a>  | 13 In Stock  |
| 50.0 x 50.0 | -     | SCHOTT<br>WG295 | 295.00 | 3.00 | <a href="#">#14-465</a> | €92,50<br><a href="#">Volume Pricing</a>  | 15 In Stock  |
| -           | 12.50 | SCHOTT<br>WG305 | 305.00 | 1.00 | <a href="#">#16-405</a> | €37,00<br><a href="#">Volume Pricing</a>  | 6 In Stock   |
| -           | 12.50 | SCHOTT<br>WG305 | 305.00 | 2.00 | <a href="#">#16-432</a> | €37,00<br><a href="#">Volume Pricing</a>  | 5 In Stock   |
| -           | 12.50 | SCHOTT<br>WG305 | 309.00 | 3.00 | <a href="#">#54-646</a> | €37,00<br><a href="#">Volume Pricing</a>  | 13 In Stock  |
| -           | 25.40 | SCHOTT<br>WG305 | 309.00 | 3.00 | <a href="#">#45-066</a> | €46,00<br><a href="#">Volume Pricing</a>  | 20+ In Stock |
| -           | 50.00 | SCHOTT<br>WG305 | 309.00 | 3.00 | <a href="#">#66-073</a> | €105,00<br><a href="#">Volume Pricing</a> | 11 In Stock  |
| 50.0 x 50.0 | -     | SCHOTT<br>WG305 | 305.00 | 1.00 | <a href="#">#14-466</a> | €92,50<br><a href="#">Volume Pricing</a>  | 14 In Stock  |
| 50.0 x 50.0 | -     | SCHOTT<br>WG305 | 305.00 | 2.00 | <a href="#">#14-467</a> | €92,50<br><a href="#">Volume Pricing</a>  | 14 In Stock  |
| 50.0 x 50.0 | -     | SCHOTT<br>WG305 | 305.00 | 3.00 | <a href="#">#14-468</a> | €92,50<br><a href="#">Volume Pricing</a>  | 14 In Stock  |
| -           | 12.50 | SCHOTT<br>WG320 | 320.00 | 1.00 | <a href="#">#16-406</a> | €37,00<br><a href="#">Volume Pricing</a>  | 6 In Stock   |
| -           | 12.50 | SCHOTT<br>WG320 | 320.00 | 2.00 | <a href="#">#16-433</a> | €37,00<br><a href="#">Volume Pricing</a>  | 5 In Stock   |
| -           | 12.50 | SCHOTT<br>WG320 | 320.00 | 3.00 | <a href="#">#46-419</a> | €37,00<br><a href="#">Volume Pricing</a>  | 20+ In Stock |
| -           | 25.40 | SCHOTT<br>WG320 | 320.00 | 3.00 | <a href="#">#46-420</a> | €46,00<br><a href="#">Volume Pricing</a>  | 17 In Stock  |
| -           | 50.00 | SCHOTT<br>WG320 | 320.00 | 3.00 | <a href="#">#66-074</a> | €105,00<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 50.0 x 50.0 | -     | SCHOTT<br>WG320 | 320.00 | 1.00 | <a href="#">#14-469</a> | €92,50<br><a href="#">Volume Pricing</a>  | 7 In Stock   |
| 50.0 x 50.0 | -     | SCHOTT<br>WG320 | 320.00 | 2.00 | <a href="#">#14-470</a> | €92,50<br><a href="#">Volume Pricing</a>  | 14 In Stock  |

|             |       |                 |        |      |                         |                                           |              |
|-------------|-------|-----------------|--------|------|-------------------------|-------------------------------------------|--------------|
| 50.0 x 50.0 | -     | SCHOTT<br>WG320 | 320.00 | 3.00 | <a href="#">#14-471</a> | €92,50<br><a href="#">Volume Pricing</a>  | 13 In Stock  |
| -           | 12.50 | SCHOTT<br>GG395 | 395.00 | 1.00 | <a href="#">#16-407</a> | €37,00<br><a href="#">Volume Pricing</a>  | 3 In Stock   |
| -           | 12.50 | SCHOTT<br>GG395 | 395.00 | 2.00 | <a href="#">#16-434</a> | €37,00<br><a href="#">Volume Pricing</a>  | 5 In Stock   |
| -           | 12.50 | SCHOTT<br>GG395 | 395.00 | 3.00 | <a href="#">#54-648</a> | €37,00<br><a href="#">Volume Pricing</a>  | 20+ In Stock |
| -           | 25.40 | SCHOTT<br>GG395 | 395.00 | 3.00 | <a href="#">#46-055</a> | €46,00<br><a href="#">Volume Pricing</a>  | 20+ In Stock |
| -           | 50.00 | SCHOTT<br>GG395 | 395.00 | 3.00 | <a href="#">#66-077</a> | €105,00<br><a href="#">Volume Pricing</a> | 5 In Stock   |
| 50.0 x 50.0 | -     | SCHOTT<br>GG395 | 395.00 | 1.00 | <a href="#">#14-472</a> | €92,50<br><a href="#">Volume Pricing</a>  | 20+ In Stock |
| 50.0 x 50.0 | -     | SCHOTT<br>GG395 | 395.00 | 2.00 | <a href="#">#14-473</a> | €92,50<br><a href="#">Volume Pricing</a>  | 13 In Stock  |
| 50.0 x 50.0 | -     | SCHOTT<br>GG395 | 395.00 | 3.00 | <a href="#">#14-474</a> | €92,50<br><a href="#">Volume Pricing</a>  | 8 In Stock   |
| 50.8 x 50.8 | -     | SCHOTT<br>GG395 | 395.00 | 3.00 | <a href="#">#46-056</a> | €105,00<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| -           | 12.50 | SCHOTT<br>GG400 | 400.00 | 1.00 | <a href="#">#16-408</a> | €37,00<br><a href="#">Volume Pricing</a>  | 7 In Stock   |
| -           | 12.50 | SCHOTT<br>GG400 | 400.00 | 2.00 | <a href="#">#16-435</a> | €37,00<br><a href="#">Volume Pricing</a>  | 4 In Stock   |
| -           | 12.50 | SCHOTT<br>GG400 | 400.00 | 3.00 | <a href="#">#46-422</a> | €37,00<br><a href="#">Volume Pricing</a>  | 20+ In Stock |
| -           | 25.40 | SCHOTT<br>GG400 | 400.00 | 3.00 | <a href="#">#46-423</a> | €46,00<br><a href="#">Volume Pricing</a>  | 20+ In Stock |
| -           | 50.00 | SCHOTT<br>GG400 | 400.00 | 3.00 | <a href="#">#66-078</a> | €105,00<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 50.0 x 50.0 | -     | SCHOTT<br>GG400 | 400.00 | 1.00 | <a href="#">#14-475</a> | €92,50<br><a href="#">Volume Pricing</a>  | 12 In Stock  |
| 50.0 x 50.0 | -     | SCHOTT<br>GG400 | 400.00 | 2.00 | <a href="#">#14-476</a> | €92,50<br><a href="#">Volume Pricing</a>  | 20+ In Stock |
| 50.0 x 50.0 | -     | SCHOTT<br>GG400 | 400.00 | 3.00 | <a href="#">#14-477</a> | €92,50<br><a href="#">Volume Pricing</a>  | 2 In Stock   |
| -           | 12.50 | SCHOTT<br>GG420 | 420.00 | 1.00 | <a href="#">#16-409</a> | €37,00<br><a href="#">Volume Pricing</a>  | 6 In Stock   |
| -           | 12.50 | SCHOTT<br>GG420 | 420.00 | 2.00 | <a href="#">#16-436</a> | €37,00<br><a href="#">Volume Pricing</a>  | 5 In Stock   |
| -           | 12.50 | SCHOTT<br>GG420 | 420.00 | 3.00 | <a href="#">#46-425</a> | €37,00<br><a href="#">Volume Pricing</a>  | 20+ In Stock |

|             |       |                 |        |      |                         |                                           |              |
|-------------|-------|-----------------|--------|------|-------------------------|-------------------------------------------|--------------|
| -           | 25.40 | SCHOTT<br>GG420 | 420.00 | 3.00 | <a href="#">#46-426</a> | €33,00<br><a href="#">Volume Pricing</a>  | 20+ In Stock |
| -           | 50.00 | SCHOTT<br>GG420 | 420.00 | 3.00 | <a href="#">#66-079</a> | €105,00<br><a href="#">Volume Pricing</a> | 16 In Stock  |
| 50.0 x 50.0 | -     | SCHOTT<br>GG420 | 420.00 | 1.00 | <a href="#">#14-478</a> | €92,50<br><a href="#">Volume Pricing</a>  | 9 In Stock   |
| 50.0 x 50.0 | -     | SCHOTT<br>GG420 | 420.00 | 2.00 | <a href="#">#14-479</a> | €92,50<br><a href="#">Volume Pricing</a>  | 9 In Stock   |
| 50.0 x 50.0 | -     | SCHOTT<br>GG420 | 420.00 | 3.00 | <a href="#">#14-480</a> | €92,50<br><a href="#">Volume Pricing</a>  | 8 In Stock   |
| 50.8 x 50.8 | -     | SCHOTT<br>GG420 | 420.00 | 3.00 | <a href="#">#46-427</a> | €105,00<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| -           | 12.50 | SCHOTT<br>GG435 | 435.00 | 1.00 | <a href="#">#16-410</a> | €37,00<br><a href="#">Volume Pricing</a>  | 7 In Stock   |
| -           | 12.50 | SCHOTT<br>GG435 | 435.00 | 2.00 | <a href="#">#16-437</a> | €37,00<br><a href="#">Volume Pricing</a>  | 1 In Stock   |
| -           | 12.50 | SCHOTT<br>GG435 | 435.00 | 3.00 | <a href="#">#54-649</a> | €37,00<br><a href="#">Volume Pricing</a>  | 20+ In Stock |
| -           | 25.40 | SCHOTT<br>GG435 | 435.00 | 3.00 | <a href="#">#32-752</a> | €46,00<br><a href="#">Volume Pricing</a>  | 12 In Stock  |
| -           | 50.00 | SCHOTT<br>GG435 | 435.00 | 3.00 | <a href="#">#66-080</a> | €105,00<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 50.0 x 50.0 | -     | SCHOTT<br>GG435 | 435.00 | 1.00 | <a href="#">#14-481</a> | €92,50<br><a href="#">Volume Pricing</a>  | 14 In Stock  |
| 50.0 x 50.0 | -     | SCHOTT<br>GG435 | 435.00 | 2.00 | <a href="#">#14-482</a> | €92,50<br><a href="#">Volume Pricing</a>  | 11 In Stock  |
| 50.0 x 50.0 | -     | SCHOTT<br>GG435 | 435.00 | 3.00 | <a href="#">#14-483</a> | €92,50<br><a href="#">Volume Pricing</a>  | 12 In Stock  |
| 50.8 x 50.8 | -     | SCHOTT<br>GG435 | 435.00 | 3.00 | <a href="#">#32-762</a> | €105,00<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| -           | 12.50 | SCHOTT<br>GG455 | 455.00 | 1.00 | <a href="#">#16-411</a> | €37,00<br><a href="#">Volume Pricing</a>  | 8 In Stock   |
| -           | 12.50 | SCHOTT<br>GG455 | 455.00 | 2.00 | <a href="#">#16-438</a> | €37,00<br><a href="#">Volume Pricing</a>  | 20+ In Stock |
| -           | 12.50 | SCHOTT<br>GG455 | 455.00 | 3.00 | <a href="#">#54-650</a> | €37,00<br><a href="#">Volume Pricing</a>  | 20+ In Stock |
| -           | 25.40 | SCHOTT<br>GG455 | 455.00 | 3.00 | <a href="#">#45-068</a> | €33,00<br><a href="#">Volume Pricing</a>  | 20+ In Stock |
| -           | 50.00 | SCHOTT<br>GG455 | 455.00 | 3.00 | <a href="#">#66-081</a> | €105,00<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 50.0 x 50.0 | -     | SCHOTT<br>GG455 | 455.00 | 1.00 | <a href="#">#14-484</a> | €92,50<br><a href="#">Volume Pricing</a>  | 8 In Stock   |

|             |       |                 |        |      |                         |                                           |              |
|-------------|-------|-----------------|--------|------|-------------------------|-------------------------------------------|--------------|
| 50.0 x 50.0 | -     | SCHOTT<br>GG455 | 455.00 | 2.00 | <a href="#">#14-485</a> | €92,50<br><a href="#">Volume Pricing</a>  | 8 In Stock   |
| 50.0 x 50.0 | -     | SCHOTT<br>GG455 | 455.00 | 3.00 | <a href="#">#14-486</a> | €92,50<br><a href="#">Volume Pricing</a>  | 13 In Stock  |
| -           | 12.50 | SCHOTT<br>GG475 | 475.00 | 1.00 | <a href="#">#16-412</a> | €37,00<br><a href="#">Volume Pricing</a>  | 10 In Stock  |
| -           | 12.50 | SCHOTT<br>GG475 | 475.00 | 2.00 | <a href="#">#16-439</a> | €37,00<br><a href="#">Volume Pricing</a>  | 5 In Stock   |
| -           | 12.50 | SCHOTT<br>GG475 | 475.00 | 3.00 | <a href="#">#54-651</a> | €37,00<br><a href="#">Volume Pricing</a>  | 20+ In Stock |
| -           | 25.40 | SCHOTT<br>GG475 | 475.00 | 3.00 | <a href="#">#46-057</a> | €46,00<br><a href="#">Volume Pricing</a>  | 20+ In Stock |
| -           | 50.00 | SCHOTT<br>GG475 | 475.00 | 3.00 | <a href="#">#66-082</a> | €105,00<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 50.0 x 50.0 | -     | SCHOTT<br>GG475 | 475.00 | 1.00 | <a href="#">#14-487</a> | €92,50<br><a href="#">Volume Pricing</a>  | 14 In Stock  |
| 50.0 x 50.0 | -     | SCHOTT<br>GG475 | 475.00 | 2.00 | <a href="#">#14-488</a> | €92,50<br><a href="#">Volume Pricing</a>  | 9 In Stock   |
| 50.0 x 50.0 | -     | SCHOTT<br>GG475 | 475.00 | 3.00 | <a href="#">#14-489</a> | €92,50<br><a href="#">Volume Pricing</a>  | 17 In Stock  |
| -           | 12.50 | SCHOTT<br>GG495 | 495.00 | 1.00 | <a href="#">#16-413</a> | €37,00<br><a href="#">Volume Pricing</a>  | 20+ In Stock |
| -           | 12.50 | SCHOTT<br>GG495 | 495.00 | 2.00 | <a href="#">#16-440</a> | €37,00<br><a href="#">Volume Pricing</a>  | 20+ In Stock |
| -           | 12.50 | SCHOTT<br>GG495 | 495.00 | 3.00 | <a href="#">#54-652</a> | €37,00<br><a href="#">Volume Pricing</a>  | 20+ In Stock |
| -           | 25.40 | SCHOTT<br>GG495 | 495.00 | 3.00 | <a href="#">#32-753</a> | €46,00<br><a href="#">Volume Pricing</a>  | 20+ In Stock |
| -           | 50.00 | SCHOTT<br>GG495 | 495.00 | 3.00 | <a href="#">#66-083</a> | €105,00<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 50.0 x 50.0 | -     | SCHOTT<br>GG495 | 495.00 | 1.00 | <a href="#">#14-490</a> | €92,50<br><a href="#">Volume Pricing</a>  | 5 In Stock   |
| 50.0 x 50.0 | -     | SCHOTT<br>GG495 | 495.00 | 2.00 | <a href="#">#14-491</a> | €92,50<br><a href="#">Volume Pricing</a>  | 8 In Stock   |
| 50.0 x 50.0 | -     | SCHOTT<br>GG495 | 495.00 | 3.00 | <a href="#">#14-492</a> | €92,50<br><a href="#">Volume Pricing</a>  | 6 In Stock   |
| -           | 12.50 | SCHOTT<br>OG515 | 515.00 | 1.00 | <a href="#">#16-414</a> | €37,00<br><a href="#">Volume Pricing</a>  | 10 In Stock  |
| -           | 12.50 | SCHOTT<br>OG515 | 515.00 | 2.00 | <a href="#">#16-441</a> | €37,00<br><a href="#">Volume Pricing</a>  | 8 In Stock   |
| -           | 12.50 | SCHOTT<br>OG515 | 515.00 | 3.00 | <a href="#">#54-653</a> | €37,00<br><a href="#">Volume Pricing</a>  | 20+ In Stock |



|             |       |                 |        |      |                         |                                           |              |
|-------------|-------|-----------------|--------|------|-------------------------|-------------------------------------------|--------------|
| -           | 25.40 | SCHOTT<br>OG515 | 515.00 | 3.00 | <a href="#">#45-069</a> | €46,00<br><a href="#">Volume Pricing</a>  | 16 In Stock  |
| -           | 50.00 | SCHOTT<br>OG515 | 515.00 | 3.00 | <a href="#">#66-085</a> | €105,00<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 50.0 x 50.0 | -     | SCHOTT<br>OG515 | 515.00 | 1.00 | <a href="#">#14-493</a> | €92,50<br><a href="#">Volume Pricing</a>  | 15 In Stock  |
| 50.0 x 50.0 | -     | SCHOTT<br>OG515 | 515.00 | 2.00 | <a href="#">#14-494</a> | €92,50<br><a href="#">Volume Pricing</a>  | 14 In Stock  |
| 50.0 x 50.0 | -     | SCHOTT<br>OG515 | 515.00 | 3.00 | <a href="#">#14-495</a> | €92,50<br><a href="#">Volume Pricing</a>  | 15 In Stock  |
| -           | 12.50 | SCHOTT<br>OG530 | 530.00 | 1.00 | <a href="#">#16-415</a> | €37,00<br><a href="#">Volume Pricing</a>  | 8 In Stock   |
| -           | 12.50 | SCHOTT<br>OG530 | 530.00 | 2.00 | <a href="#">#16-442</a> | €37,00<br><a href="#">Volume Pricing</a>  | 8 In Stock   |
| -           | 12.50 | SCHOTT<br>OG530 | 530.00 | 3.00 | <a href="#">#54-654</a> | €37,00<br><a href="#">Volume Pricing</a>  | 2 In Stock   |
| -           | 25.40 | SCHOTT<br>OG530 | 530.00 | 3.00 | <a href="#">#46-059</a> | €33,00<br><a href="#">Volume Pricing</a>  | 20+ In Stock |
| -           | 50.00 | SCHOTT<br>OG530 | 530.00 | 3.00 | <a href="#">#66-086</a> | €105,00<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 50.0 x 50.0 | -     | SCHOTT<br>OG530 | 530.00 | 1.00 | <a href="#">#14-496</a> | €92,50<br><a href="#">Volume Pricing</a>  | 15 In Stock  |
| 50.0 x 50.0 | -     | SCHOTT<br>OG530 | 530.00 | 2.00 | <a href="#">#14-497</a> | €92,50<br><a href="#">Volume Pricing</a>  | 11 In Stock  |
| 50.0 x 50.0 | -     | SCHOTT<br>OG530 | 530.00 | 3.00 | <a href="#">#14-498</a> | €92,50<br><a href="#">Volume Pricing</a>  | 9 In Stock   |
| -           | 12.50 | SCHOTT<br>OG550 | 550.00 | 1.00 | <a href="#">#16-416</a> | €37,00<br><a href="#">Volume Pricing</a>  | 4 In Stock   |
| -           | 12.50 | SCHOTT<br>OG550 | 550.00 | 2.00 | <a href="#">#16-443</a> | €37,00<br><a href="#">Volume Pricing</a>  | 7 In Stock   |
| -           | 12.50 | SCHOTT<br>OG550 | 550.00 | 3.00 | <a href="#">#54-655</a> | €37,00<br><a href="#">Volume Pricing</a>  | 20+ In Stock |
| -           | 25.40 | SCHOTT<br>OG550 | 550.00 | 3.00 | <a href="#">#32-754</a> | €46,00<br><a href="#">Volume Pricing</a>  | 20+ In Stock |
| -           | 50.00 | SCHOTT<br>OG550 | 550.00 | 3.00 | <a href="#">#66-088</a> | €105,00<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 50.0 x 50.0 | -     | SCHOTT<br>OG550 | 550.00 | 1.00 | <a href="#">#14-499</a> | €92,50<br><a href="#">Volume Pricing</a>  | 13 In Stock  |
| 50.0 x 50.0 | -     | SCHOTT<br>OG550 | 550.00 | 2.00 | <a href="#">#14-500</a> | €92,50<br><a href="#">Volume Pricing</a>  | 16 In Stock  |
| 50.0 x 50.0 | -     | SCHOTT<br>OG550 | 550.00 | 3.00 | <a href="#">#14-502</a> | €92,50<br><a href="#">Volume Pricing</a>  | 5 In Stock   |

|             |       |                 |        |      |                         |                                           |              |
|-------------|-------|-----------------|--------|------|-------------------------|-------------------------------------------|--------------|
| -           | 12.50 | SCHOTT<br>OG570 | 570.00 | 1.00 | <a href="#">#16-417</a> | €37,00<br><a href="#">Volume Pricing</a>  | 4 In Stock   |
| -           | 12.50 | SCHOTT<br>OG570 | 570.00 | 2.00 | <a href="#">#16-444</a> | €37,00<br><a href="#">Volume Pricing</a>  | 4 In Stock   |
| -           | 12.50 | SCHOTT<br>OG570 | 570.00 | 3.00 | <a href="#">#54-656</a> | €37,00<br><a href="#">Volume Pricing</a>  | 20+ In Stock |
| -           | 25.40 | SCHOTT<br>OG570 | 570.00 | 3.00 | <a href="#">#46-061</a> | €33,00<br><a href="#">Volume Pricing</a>  | 20+ In Stock |
| -           | 50.00 | SCHOTT<br>OG570 | 570.00 | 3.00 | <a href="#">#66-090</a> | €105,00<br><a href="#">Volume Pricing</a> | 10 In Stock  |
| 50.0 x 50.0 | -     | SCHOTT<br>OG570 | 570.00 | 1.00 | <a href="#">#14-505</a> | €92,50<br><a href="#">Volume Pricing</a>  | 14 In Stock  |
| 50.0 x 50.0 | -     | SCHOTT<br>OG570 | 570.00 | 2.00 | <a href="#">#14-506</a> | €92,50<br><a href="#">Volume Pricing</a>  | 14 In Stock  |
| 50.0 x 50.0 | -     | SCHOTT<br>OG570 | 570.00 | 3.00 | <a href="#">#14-507</a> | €92,50<br><a href="#">Volume Pricing</a>  | 17 In Stock  |
| -           | 12.50 | SCHOTT<br>OG590 | 590.00 | 1.00 | <a href="#">#16-418</a> | €37,00<br><a href="#">Volume Pricing</a>  | 5 In Stock   |
| -           | 12.50 | SCHOTT<br>OG590 | 590.00 | 2.00 | <a href="#">#16-445</a> | €37,00<br><a href="#">Volume Pricing</a>  | 10 In Stock  |
| -           | 12.50 | SCHOTT<br>OG590 | 590.00 | 3.00 | <a href="#">#54-657</a> | €37,00<br><a href="#">Volume Pricing</a>  | 14 In Stock  |
| -           | 25.40 | SCHOTT<br>OG590 | 590.00 | 3.00 | <a href="#">#46-063</a> | €46,00<br><a href="#">Volume Pricing</a>  | 20+ In Stock |
| -           | 50.00 | SCHOTT<br>OG590 | 590.00 | 3.00 | <a href="#">#66-092</a> | €105,00<br><a href="#">Volume Pricing</a> | 5 In Stock   |
| 50.0 x 50.0 | -     | SCHOTT<br>OG590 | 590.00 | 1.00 | <a href="#">#14-508</a> | €92,50<br><a href="#">Volume Pricing</a>  | 5 In Stock   |
| 50.0 x 50.0 | -     | SCHOTT<br>OG590 | 590.00 | 2.00 | <a href="#">#14-509</a> | €92,50<br><a href="#">Volume Pricing</a>  | 12 In Stock  |
| 50.0 x 50.0 | -     | SCHOTT<br>OG590 | 590.00 | 3.00 | <a href="#">#14-510</a> | €92,50<br><a href="#">Volume Pricing</a>  | 11 In Stock  |
| 50.8 x 50.8 | -     | SCHOTT<br>OG590 | 590.00 | 3.00 | <a href="#">#46-064</a> | €105,00<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| -           | 12.50 | SCHOTT<br>RG610 | 610.00 | 1.00 | <a href="#">#16-419</a> | €37,00<br><a href="#">Volume Pricing</a>  | 5 In Stock   |
| -           | 12.50 | SCHOTT<br>RG610 | 610.00 | 2.00 | <a href="#">#16-446</a> | €37,00<br><a href="#">Volume Pricing</a>  | 6 In Stock   |
| -           | 12.50 | SCHOTT<br>RG610 | 610.00 | 3.00 | <a href="#">#46-428</a> | €37,00<br><a href="#">Volume Pricing</a>  | 20+ In Stock |
| -           | 25.40 | SCHOTT<br>RG610 | 610.00 | 3.00 | <a href="#">#46-429</a> | €46,00<br><a href="#">Volume Pricing</a>  | 20+ In Stock |

|             |       |                 |        |      |                         |                                           |              |
|-------------|-------|-----------------|--------|------|-------------------------|-------------------------------------------|--------------|
| -           | 50.00 | SCHOTT<br>RG610 | 610.00 | 3.00 | <a href="#">#66-094</a> | €105,00<br><a href="#">Volume Pricing</a> | 2 In Stock   |
| 50.0 x 50.0 | -     | SCHOTT<br>RG610 | 610.00 | 1.00 | <a href="#">#14-511</a> | €92,50<br><a href="#">Volume Pricing</a>  | 6 In Stock   |
| 50.0 x 50.0 | -     | SCHOTT<br>RG610 | 610.00 | 2.00 | <a href="#">#14-512</a> | €92,50<br><a href="#">Volume Pricing</a>  | 7 In Stock   |
| 50.0 x 50.0 | -     | SCHOTT<br>RG610 | 610.00 | 3.00 | <a href="#">#14-513</a> | €92,50<br><a href="#">Volume Pricing</a>  | 16 In Stock  |
| -           | 12.50 | SCHOTT<br>RG630 | 630.00 | 1.00 | <a href="#">#16-420</a> | €37,00<br><a href="#">Volume Pricing</a>  | 2 In Stock   |
| -           | 12.50 | SCHOTT<br>RG630 | 630.00 | 2.00 | <a href="#">#16-447</a> | €37,00<br><a href="#">Volume Pricing</a>  | 9 In Stock   |
| -           | 12.50 | SCHOTT<br>RG630 | 630.00 | 3.00 | <a href="#">#54-658</a> | €37,00<br><a href="#">Volume Pricing</a>  | 16 In Stock  |
| -           | 25.40 | SCHOTT<br>RG630 | 630.00 | 3.00 | <a href="#">#32-755</a> | €33,00<br><a href="#">Volume Pricing</a>  | 8 In Stock   |
| -           | 50.00 | SCHOTT<br>RG630 | 630.00 | 3.00 | <a href="#">#66-096</a> | €105,00<br><a href="#">Volume Pricing</a> | 13 In Stock  |
| 50.0 x 50.0 | -     | SCHOTT<br>RG630 | 630.00 | 1.00 | <a href="#">#14-514</a> | €92,50<br><a href="#">Volume Pricing</a>  | 20+ In Stock |
| 50.0 x 50.0 | -     | SCHOTT<br>RG630 | 630.00 | 2.00 | <a href="#">#14-515</a> | €92,50<br><a href="#">Volume Pricing</a>  | 14 In Stock  |
| 50.0 x 50.0 | -     | SCHOTT<br>RG630 | 630.00 | 3.00 | <a href="#">#14-516</a> | €92,50<br><a href="#">Volume Pricing</a>  | 14 In Stock  |
| -           | 12.50 | SCHOTT<br>RG645 | 645.00 | 1.00 | <a href="#">#16-421</a> | €37,00<br><a href="#">Volume Pricing</a>  | 5 In Stock   |
| -           | 12.50 | SCHOTT<br>RG645 | 645.00 | 2.00 | <a href="#">#16-448</a> | €37,00<br><a href="#">Volume Pricing</a>  | 20+ In Stock |
| -           | 12.50 | SCHOTT<br>RG645 | 645.00 | 3.00 | <a href="#">#64-512</a> | €37,00<br><a href="#">Volume Pricing</a>  | 5 In Stock   |
| -           | 25.40 | SCHOTT<br>RG645 | 645.00 | 3.00 | <a href="#">#64-513</a> | €33,00<br><a href="#">Volume Pricing</a>  | 20+ In Stock |
| -           | 50.00 | SCHOTT<br>RG645 | 645.00 | 3.00 | <a href="#">#66-097</a> | €105,00<br><a href="#">Volume Pricing</a> | 7 In Stock   |
| 50.0 x 50.0 | -     | SCHOTT<br>RG645 | 645.00 | 1.00 | <a href="#">#14-517</a> | €92,50<br><a href="#">Volume Pricing</a>  | 13 In Stock  |
| 50.0 x 50.0 | -     | SCHOTT<br>RG645 | 645.00 | 2.00 | <a href="#">#14-518</a> | €92,50<br><a href="#">Volume Pricing</a>  | 10 In Stock  |
| 50.0 x 50.0 | -     | SCHOTT<br>RG645 | 645.00 | 3.00 | <a href="#">#14-519</a> | €92,50<br><a href="#">Volume Pricing</a>  | 20+ In Stock |

[#64-514 Clearance](#)



Clearance

Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.

50.8 x 50.8

-

SCHOTT  
RG645

645.00

3.00

€59,50

Contact Us

|             |       |                 |        |      |                         |                                           |              |
|-------------|-------|-----------------|--------|------|-------------------------|-------------------------------------------|--------------|
| -           | 12.50 | SCHOTT<br>RG665 | 665.00 | 1.00 | <a href="#">#16-422</a> | €37,00<br><a href="#">Volume Pricing</a>  | 4 In Stock   |
| -           | 12.50 | SCHOTT<br>RG665 | 665.00 | 2.00 | <a href="#">#16-449</a> | €37,00<br><a href="#">Volume Pricing</a>  | 5 In Stock   |
| -           | 12.50 | SCHOTT<br>RG665 | 665.00 | 3.00 | <a href="#">#54-659</a> | €37,00<br><a href="#">Volume Pricing</a>  | 20+ In Stock |
| -           | 25.40 | SCHOTT<br>RG665 | 665.00 | 3.00 | <a href="#">#45-070</a> | €46,00<br><a href="#">Volume Pricing</a>  | 20+ In Stock |
| -           | 50.00 | SCHOTT<br>RG665 | 665.00 | 3.00 | <a href="#">#66-099</a> | €105,00<br><a href="#">Volume Pricing</a> | 5 In Stock   |
| 50.0 x 50.0 | -     | SCHOTT<br>RG665 | 665.00 | 1.00 | <a href="#">#14-520</a> | €92,50<br><a href="#">Volume Pricing</a>  | 14 In Stock  |
| 50.0 x 50.0 | -     | SCHOTT<br>RG665 | 665.00 | 2.00 | <a href="#">#14-521</a> | €92,50<br><a href="#">Volume Pricing</a>  | 14 In Stock  |
| 50.0 x 50.0 | -     | SCHOTT<br>RG665 | 665.00 | 3.00 | <a href="#">#14-522</a> | €92,50<br><a href="#">Volume Pricing</a>  | 13 In Stock  |
| -           | 12.50 | SCHOTT<br>RG695 | 695.00 | 1.00 | <a href="#">#16-423</a> | €37,00<br><a href="#">Volume Pricing</a>  | 2 In Stock   |
| -           | 12.50 | SCHOTT<br>RG695 | 695.00 | 2.00 | <a href="#">#16-450</a> | €37,00<br><a href="#">Volume Pricing</a>  | 6 In Stock   |
| -           | 12.50 | SCHOTT<br>RG695 | 695.00 | 3.00 | <a href="#">#54-660</a> | €37,00<br><a href="#">Volume Pricing</a>  | 20+ In Stock |
| -           | 25.40 | SCHOTT<br>RG695 | 695.00 | 3.00 | <a href="#">#32-756</a> | €33,00<br><a href="#">Volume Pricing</a>  | 20+ In Stock |
| -           | 50.00 | SCHOTT<br>RG695 | 695.00 | 3.00 | <a href="#">#66-100</a> | €105,00<br><a href="#">Volume Pricing</a> | 17 In Stock  |

|             |       |                 |        |      |                         |                                           |              |
|-------------|-------|-----------------|--------|------|-------------------------|-------------------------------------------|--------------|
| 50.0 x 50.0 | -     | SCHOTT<br>RG695 | 695.00 | 1.00 | <a href="#">#14-523</a> | €92,50<br><a href="#">Volume Pricing</a>  | 13 In Stock  |
| 50.0 x 50.0 | -     | SCHOTT<br>RG695 | 695.00 | 2.00 | <a href="#">#14-524</a> | €92,50<br><a href="#">Volume Pricing</a>  | 12 In Stock  |
| 50.0 x 50.0 | -     | SCHOTT<br>RG695 | 695.00 | 3.00 | <a href="#">#14-525</a> | €92,50<br><a href="#">Volume Pricing</a>  | 13 In Stock  |
| -           | 12.50 | SCHOTT<br>RG715 | 715.00 | 1.00 | <a href="#">#16-424</a> | €37,00<br><a href="#">Volume Pricing</a>  | 2 In Stock   |
| -           | 12.50 | SCHOTT<br>RG715 | 715.00 | 2.00 | <a href="#">#16-451</a> | €37,00<br><a href="#">Volume Pricing</a>  | 7 In Stock   |
| -           | 12.50 | SCHOTT<br>RG715 | 715.00 | 3.00 | <a href="#">#54-661</a> | €37,00<br><a href="#">Volume Pricing</a>  | 20+ In Stock |
| -           | 25.40 | SCHOTT<br>RG715 | 715.00 | 3.00 | <a href="#">#46-065</a> | €52,50<br><a href="#">Volume Pricing</a>  | 20+ In Stock |
| -           | 50.00 | SCHOTT<br>RG715 | 715.00 | 3.00 | <a href="#">#66-101</a> | €105,00<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 50.0 x 50.0 | -     | SCHOTT<br>RG715 | 715.00 | 1.00 | <a href="#">#14-526</a> | €92,50<br><a href="#">Volume Pricing</a>  | 17 In Stock  |
| 50.0 x 50.0 | -     | SCHOTT<br>RG715 | 715.00 | 2.00 | <a href="#">#14-527</a> | €92,50<br><a href="#">Volume Pricing</a>  | 14 In Stock  |
| 50.0 x 50.0 | -     | SCHOTT<br>RG715 | 715.00 | 3.00 | <a href="#">#14-528</a> | €92,50<br><a href="#">Volume Pricing</a>  | 20+ In Stock |
| -           | 12.50 | SCHOTT<br>RG9   | 726.00 | 1.00 | <a href="#">#16-425</a> | €37,00<br><a href="#">Volume Pricing</a>  | 3 In Stock   |
| -           | 12.50 | SCHOTT<br>RG9   | 726.00 | 2.00 | <a href="#">#16-452</a> | €37,00<br><a href="#">Volume Pricing</a>  | 16 In Stock  |
| -           | 12.50 | SCHOTT<br>RG9   | 726.00 | 3.00 | <a href="#">#16-457</a> | €37,00<br><a href="#">Volume Pricing</a>  | 8 In Stock   |
| -           | 25.40 | SCHOTT<br>RG9   | 726.00 | 3.00 | <a href="#">#84-903</a> | €35,00<br><a href="#">Volume Pricing</a>  | 11 In Stock  |
| -           | 50.00 | SCHOTT<br>RG9   | 726.00 | 3.00 | <a href="#">#16-458</a> | €105,00<br><a href="#">Volume Pricing</a> | 12 In Stock  |
| 50.0 x 50.0 | -     | SCHOTT<br>RG9   | 726.00 | 1.00 | <a href="#">#14-529</a> | €92,50<br><a href="#">Volume Pricing</a>  | 15 In Stock  |
| 50.0 x 50.0 | -     | SCHOTT<br>RG9   | 726.00 | 2.00 | <a href="#">#14-530</a> | €92,50<br><a href="#">Volume Pricing</a>  | 5 In Stock   |
| 50.0 x 50.0 | -     | SCHOTT<br>RG9   | 726.00 | 3.00 | <a href="#">#14-531</a> | €92,50<br><a href="#">Volume Pricing</a>  | 20+ In Stock |
| -           | 12.50 | SCHOTT<br>RG780 | 780.00 | 1.00 | <a href="#">#16-426</a> | €37,00<br><a href="#">Volume Pricing</a>  | 5 In Stock   |
| -           | 12.50 | SCHOTT<br>RG780 | 780.00 | 2.00 | <a href="#">#16-453</a> | €37,00<br><a href="#">Volume Pricing</a>  | 16 In Stock  |

|             |       |                 |        |      |                         |                                           |              |
|-------------|-------|-----------------|--------|------|-------------------------|-------------------------------------------|--------------|
| -           | 12.50 | SCHOTT<br>RG780 | 780.00 | 3.00 | <a href="#">#54-662</a> | €37,00<br><a href="#">Volume Pricing</a>  | 20+ In Stock |
| -           | 25.40 | SCHOTT<br>RG780 | 780.00 | 3.00 | <a href="#">#32-757</a> | €52,50<br><a href="#">Volume Pricing</a>  | 20+ In Stock |
| -           | 50.00 | SCHOTT<br>RG780 | 780.00 | 3.00 | <a href="#">#66-104</a> | €105,00<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 50.0 x 50.0 | -     | SCHOTT<br>RG780 | 780.00 | 1.00 | <a href="#">#14-532</a> | €92,50<br><a href="#">Volume Pricing</a>  | 14 In Stock  |
| 50.0 x 50.0 | -     | SCHOTT<br>RG780 | 780.00 | 2.00 | <a href="#">#14-533</a> | €92,50<br><a href="#">Volume Pricing</a>  | 10 In Stock  |
| 50.0 x 50.0 | -     | SCHOTT<br>RG780 | 780.00 | 3.00 | <a href="#">#14-534</a> | €92,50<br><a href="#">Volume Pricing</a>  | 12 In Stock  |
| 50.8 x 50.8 | -     | SCHOTT<br>RG780 | 780.00 | 3.00 | <a href="#">#32-767</a> | €105,00<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| -           | 12.50 | SCHOTT<br>RG830 | 830.00 | 1.00 | <a href="#">#16-427</a> | €37,00<br><a href="#">Volume Pricing</a>  | 4 In Stock   |
| -           | 12.50 | SCHOTT<br>RG830 | 830.00 | 2.00 | <a href="#">#16-454</a> | €37,00<br><a href="#">Volume Pricing</a>  | 5 In Stock   |
| -           | 12.50 | SCHOTT<br>RG830 | 830.00 | 3.00 | <a href="#">#54-663</a> | €37,00<br><a href="#">Volume Pricing</a>  | 20+ In Stock |
| -           | 25.40 | SCHOTT<br>RG830 | 830.00 | 3.00 | <a href="#">#32-758</a> | €33,00<br><a href="#">Volume Pricing</a>  | 20+ In Stock |
| -           | 50.00 | SCHOTT<br>RG830 | 830.00 | 3.00 | <a href="#">#66-106</a> | €105,00<br><a href="#">Volume Pricing</a> | 20+ In Stock |
| 50.0 x 50.0 | -     | SCHOTT<br>RG830 | 830.00 | 1.00 | <a href="#">#14-535</a> | €92,50<br><a href="#">Volume Pricing</a>  | 14 In Stock  |
| 50.0 x 50.0 | -     | SCHOTT<br>RG830 | 830.00 | 2.00 | <a href="#">#14-536</a> | €92,50<br><a href="#">Volume Pricing</a>  | 13 In Stock  |
| 50.0 x 50.0 | -     | SCHOTT<br>RG830 | 830.00 | 3.00 | <a href="#">#14-537</a> | €92,50<br><a href="#">Volume Pricing</a>  | 8 In Stock   |
| -           | 12.50 | SCHOTT<br>RG850 | 850.00 | 1.00 | <a href="#">#16-428</a> | €37,00<br><a href="#">Volume Pricing</a>  | 10 In Stock  |
| -           | 12.50 | SCHOTT<br>RG850 | 850.00 | 2.00 | <a href="#">#16-455</a> | €37,00<br><a href="#">Volume Pricing</a>  | Contact Us   |
| -           | 12.50 | SCHOTT<br>RG850 | 850.00 | 3.00 | <a href="#">#54-664</a> | €37,00<br><a href="#">Volume Pricing</a>  | Contact Us   |
| -           | 25.40 | SCHOTT<br>RG850 | 850.00 | 3.00 | <a href="#">#32-759</a> | €65,00<br><a href="#">Volume Pricing</a>  | 17 In Stock  |
| -           | 50.00 | SCHOTT<br>RG850 | 850.00 | 3.00 | <a href="#">#66-107</a> | €105,00<br><a href="#">Volume Pricing</a> | Contact Us   |
| 50.0 x 50.0 | -     | SCHOTT<br>RG850 | 850.00 | 1.00 | <a href="#">#14-538</a> | €95,00<br><a href="#">Volume Pricing</a>  | 8 In Stock   |

|             |       |                  |          |      |                         |                                           |              |
|-------------|-------|------------------|----------|------|-------------------------|-------------------------------------------|--------------|
| 50.0 x 50.0 | -     | SCHOTT<br>RG850  | 850.00   | 2.00 | <a href="#">#14-539</a> | €95,00<br><a href="#">Volume Pricing</a>  | 13 In Stock  |
| 50.0 x 50.0 | -     | SCHOTT<br>RG850  | 850.00   | 3.00 | <a href="#">#14-540</a> | €95,00<br><a href="#">Volume Pricing</a>  | 13 In Stock  |
| -           | 12.50 | SCHOTT<br>RG1000 | 1,000.00 | 1.00 | <a href="#">#16-429</a> | €37,00<br><a href="#">Volume Pricing</a>  | 14 In Stock  |
| -           | 12.50 | SCHOTT<br>RG1000 | 1,000.00 | 2.00 | <a href="#">#16-456</a> | €37,00<br><a href="#">Volume Pricing</a>  | 1 In Stock   |
| -           | 12.50 | SCHOTT<br>RG1000 | 1,000.00 | 3.00 | <a href="#">#54-665</a> | €37,00<br><a href="#">Volume Pricing</a>  | 20+ In Stock |
| -           | 25.40 | SCHOTT<br>RG1000 | 1,000.00 | 3.00 | <a href="#">#32-760</a> | €46,00<br><a href="#">Volume Pricing</a>  | 20+ In Stock |
| -           | 50.00 | SCHOTT<br>RG1000 | 1,000.00 | 3.00 | <a href="#">#66-108</a> | €105,00<br><a href="#">Volume Pricing</a> | 4 In Stock   |
| 50.0 x 50.0 | -     | SCHOTT<br>RG1000 | 1,000.00 | 1.00 | <a href="#">#14-541</a> | €92,50<br><a href="#">Volume Pricing</a>  | 14 In Stock  |
| 50.0 x 50.0 | -     | SCHOTT<br>RG1000 | 1,000.00 | 2.00 | <a href="#">#14-542</a> | €92,50<br><a href="#">Volume Pricing</a>  | 8 In Stock   |
| 50.0 x 50.0 | -     | SCHOTT<br>RG1000 | 1,000.00 | 3.00 | <a href="#">#14-543</a> | €92,50<br><a href="#">Volume Pricing</a>  | 20+ In Stock |



Copyright 2023 | Edmund Optics, Ltd Unit 1, Opus Avenue, Nether Poppleton, York, YO26 6BL, UK  
 Phone: 1-800-363-1992 :  
[www.edmundoptics.com](http://www.edmundoptics.com)